


**Rittal – The System.**

Faster – better – everywhere.

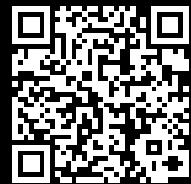

**SK 3238.066**

**Chopped fiber filter mat**

State: 2026-01-15 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



FRIEDHELM LOH GROUP

# SK 3238.066 - Chopped fiber filter mat

Replacement filter mats for roof fans, filter fans or thermoelectric coolers to effectively protect control enclosure components from dirt, dust and water.

## Features

Model No.	SK 3238.066
Version	for EMC filter fans
Product description	Made of chopped-fiber mat with a progressive construction. Temperature-resistant to 100 °C, self-extinguishing category F1 to DIN 53 438. Dust-laden air side: Open structure. Clean air side: Closed structure. Reliable filtering of virtually all types of dust from a particle size of 10 µm.
Material	Copper/nickel/chrome-coated chemical fibers
Note	Performance data, protection category, and device approvals are only guaranteed when used in conjunction with original Rittal filter mats.
Suitable for Model No.	3238.6..
Dimensions	Width: 125 mm Height: 125 mm Depth: 12 mm
Filter class	to DIN EN 779: G2
Packaging unit	5 pc(s).
Net weight	0.015
Gross weight	0.02
Customs tariff number	56039390
EAN	4028177666221
ETIM 9	EC002513
ETIM 8	EC002513
ECLASS 8.0	27180706

# Approvals

---

Approvals	UR + C-UR (recognized)
Certificates	EAC