


Rittal – The System.

Faster – better – everywhere.

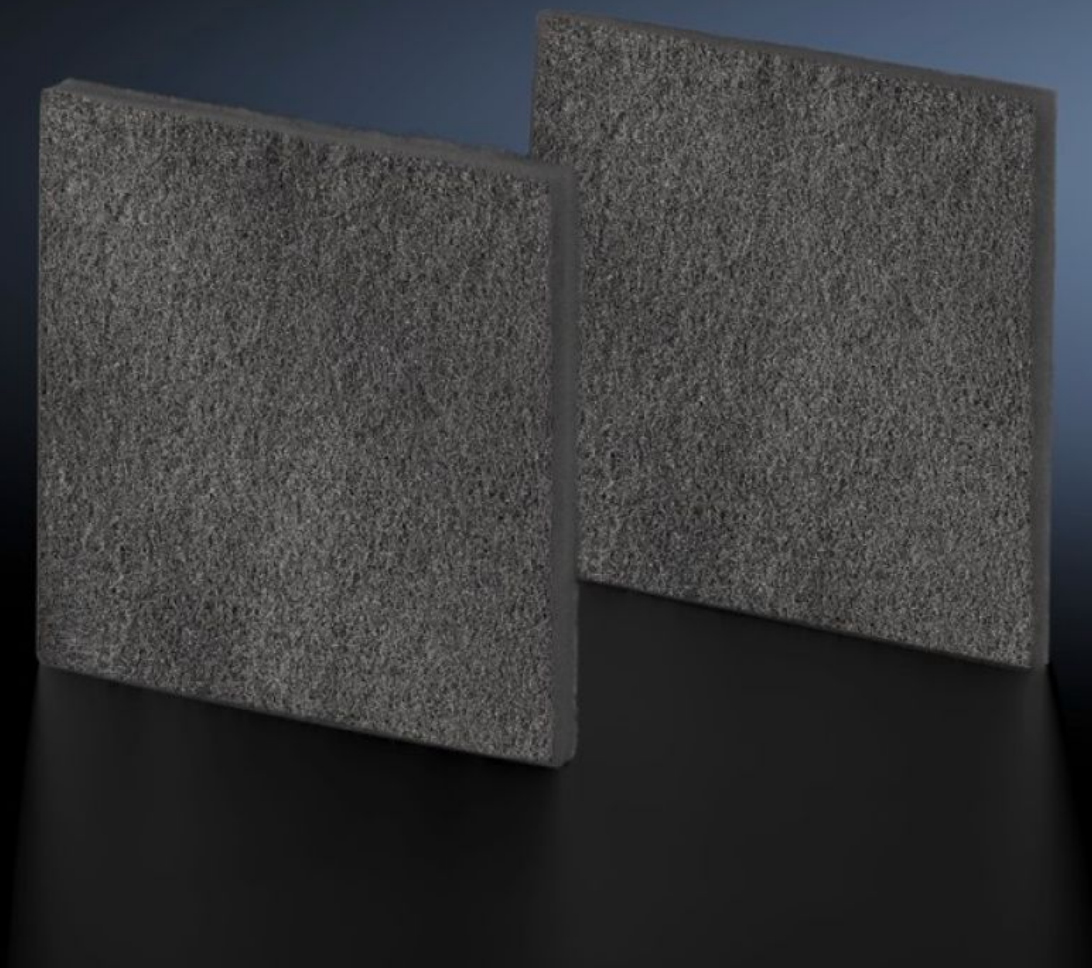

SK 3238.066

Chopped fiber filter mat

State: 2025-09-07 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SK 3238.066 - Chopped fiber filter mat

Replacement filter mats for roof fans, filter fans or thermoelectric coolers to effectively protect control enclosure components from dirt, dust and water.

Features

| | |
|------------------------|---|
| Model No. | SK 3238.066 |
| Version | for EMC filter fans |
| Product description | Made of chopped-fiber mat with a progressive construction. Temperature-resistant to 100 °C, self-extinguishing category F1 to DIN 53 438. Dust-laden air side: Open structure. Clean air side: Closed structure. Reliable filtering of virtually all types of dust from a particle size of 10 µm. |
| Material | Copper/nickel/chrome-coated chemical fibers |
| Note | Performance data, protection category, and device approvals are only guaranteed when used in conjunction with original Rittal filter mats. |
| Suitable for Model No. | 3238.6.. |
| Dimensions | Width: 125 mm Height: 125 mm Depth: 12 mm |
| Filter class | to DIN EN 779: G2 |
| Packaging unit | 5 pc(s). |
| Net weight | 0.015 |
| Gross weight | 0.02 |
| Customs tariff number | 56039390 |
| EAN | 4028177666221 |
| ETIM 9 | EC002513 |
| ETIM 8 | EC002513 |
| ECLASS 8.0 | 27180706 |

Approvals

| | |
|--------------|------------------------|
| Approvals | UR + C-UR (recognized) |
| Certificates | EAC |