

Rittal – The System.

Faster – better – everywhere.



AS 4050.435

Wiring duct cutter MC125


State: 2026-02-02 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



FRIEDHELM LOH GROUP

AS 4050.435 - Wiring duct cutter MC125

For the manual cutting of wiring ducts, with adjustable length stop for the material being cut. Anodized contact surface with laser-engraved marking in millimeters and inch scales. Safe machining due to integrated finger guard. Designed for mounting on a workbench.

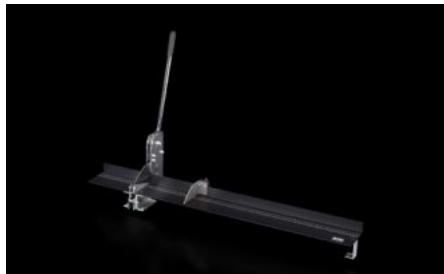

Features

Model No.	AS 4050.435
Product description	For the manual cutting of wiring ducts, with adjustable length stop for the material being cut. Anodized contact surface with laser-engraved marking in millimeters and inch scales. Safe machining due to integrated finger guard. Designed for mounting on a workbench.
Benefits	Enables economic manual cable duct cutting Easier for cutting wiring ducts to length compared to sawing by hand
Support area	Width: 1,332 mm Height: 798 mm Depth: 405 mm
Insertion height (max.)	28 mm
Machinable wall thickness of cable ducts (max.)	2.5 mm

Features

Maximum workable width, cable duct 125 mm

Workable material Plastic

Packaging unit 1 pc(s).

Net weight 14.3

Gross weight 15.43

Customs tariff number 84778095

EAN 4028177930933

ETIM 9 EC002778

ETIM 8 EC002778

ECLASS 8.0 17139290