
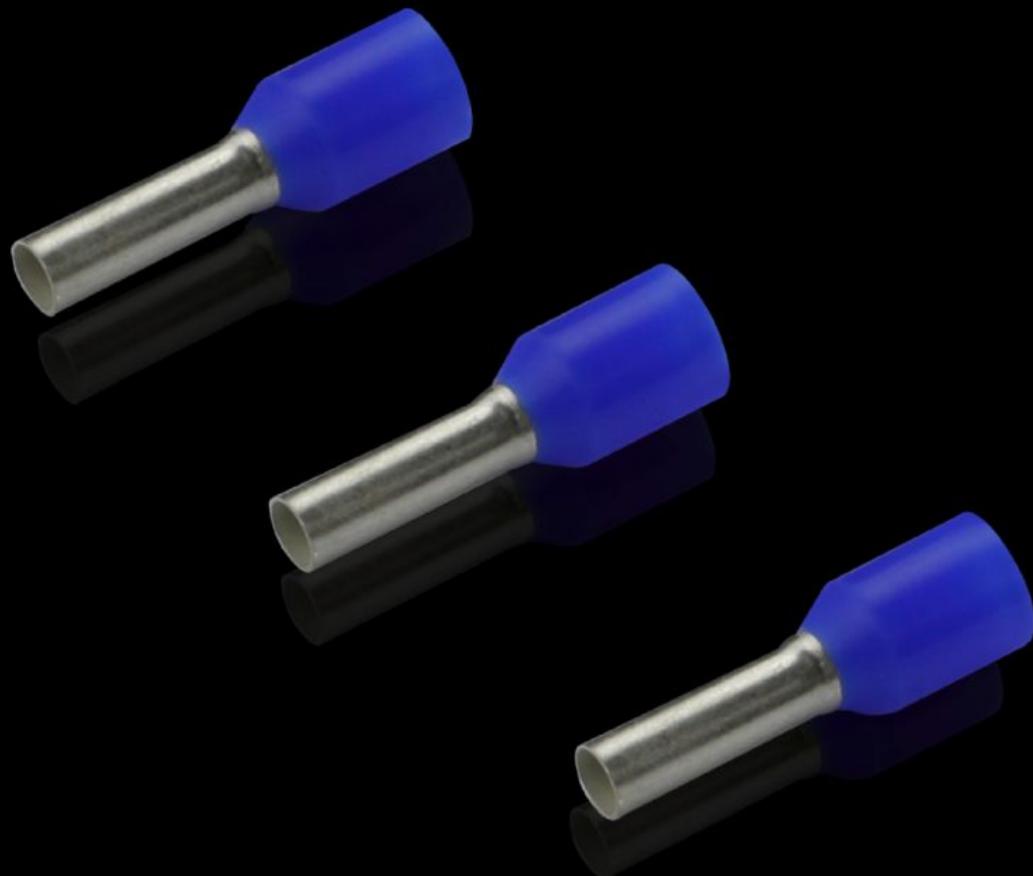


# Rittal – The System.

Faster – better – everywhere.

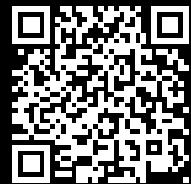

## AS 4050.734

## Wire end ferrule

State: 2026-01-21 (Source: [rittal.com/ca-en](https://rittal.com/ca-en))

# AS 4050.734 - Wire end ferrule Loose

With plastic collar.

## Features

Model No.	AS 4050.734
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	Blue
Length	8 mm
AWG	14
Internal diameter	4.2 mm
For cross section	2.5 mm <sup>2</sup>
DIN color code	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Suitable for Model No.	4051.205 4051.210 4050.452
Delivery form	Loose
Packaging unit	500 pc(s).
Net weight	0.5
Customs tariff number	85369010
EAN	4028177805026
ETIM 9	EC000005

# Features

---

ETIM 8 EC000005

---

ECLASS 8.0 36659290

# Approvals

---

Approvals UL + C-UL (listed)  
UR