


Rittal – The System.

Faster – better – everywhere.

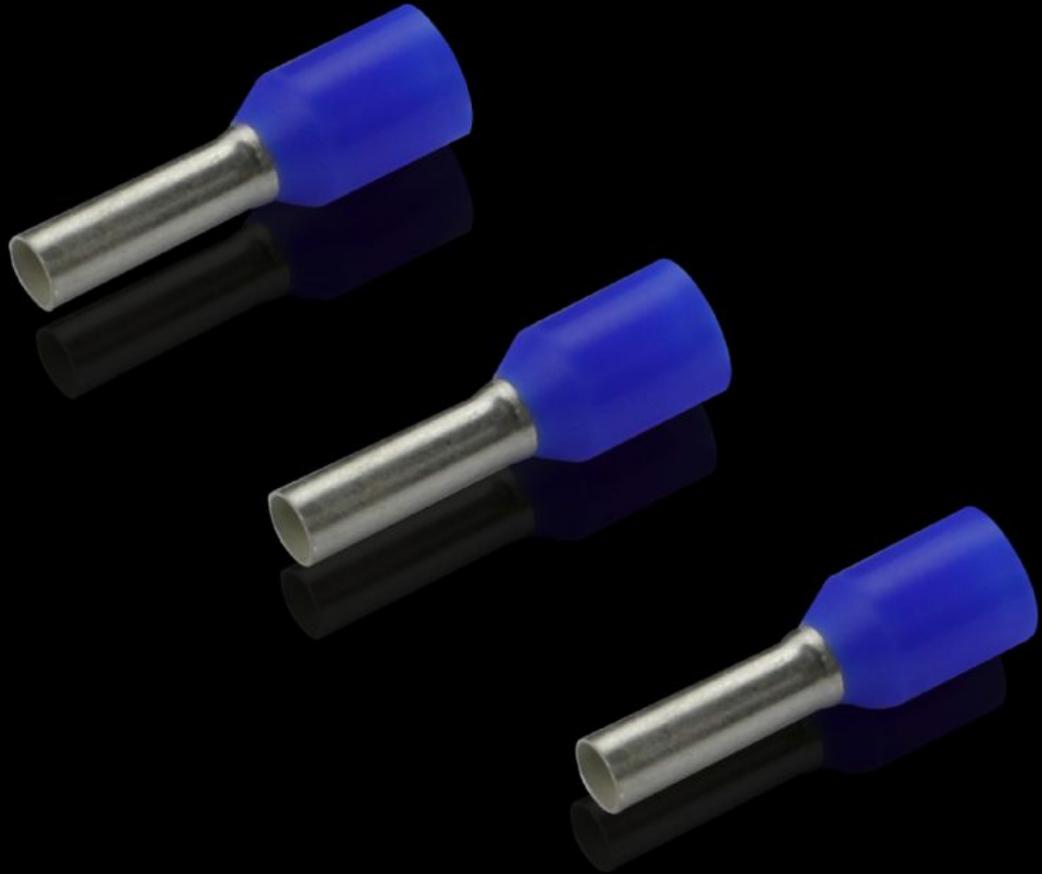

AS 4050.734 Wire end ferrule

State: 2026-05-07 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.734 - Wire end ferrule Loose

With plastic collar.

Features

| | |
|--------------------------|--|
| Model No. | AS 4050.734 |
| Product description | With plastic collar. |
| Technical specifications | Heat resistant up to 105 °C |
| Material | E-Cu, tin-plated Plastic collar: Polypropylene |
| Color | Blue |
| Length | 8 mm |
| AWG | 14 |
| Internal diameter | 4.2 mm |
| For cross section | 2.5 mm ² |
| DIN color code | Yes |
| Note | UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative. |
| Standards | AEH DIN 46228 |
| Suitable for Model No. | 4051.205 4051.210 4050.452 |
| Delivery form | Loose |
| Packaging unit | 500 pc(s). |
| Net weight | 0.5 kg |
| Customs tariff number | 85369010 |
| ETIM 9 | EC000005 |
| ETIM 8 | EC000005 |

Features

| | |
|---------------------|--|
| ECLASS 8.0 | 36659290 |
| Product description | Wire end ferrules for wire assembly, 2.5 mm ² , blue, loose, 8 mm |

Approvals

| | |
|-----------|--------------------------|
| Approvals | UL + C-UL (listed) UR |
|-----------|--------------------------|
