


**Rittal – The System.**

Faster – better – everywhere.

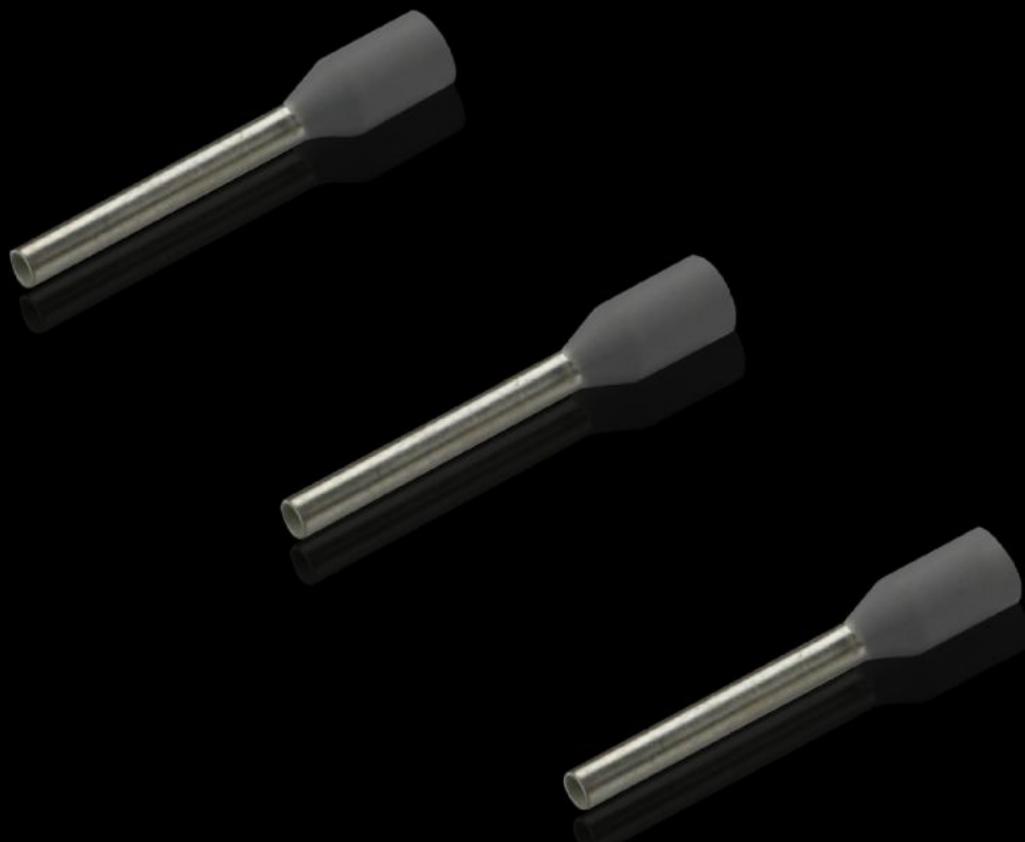

# AS 4050.738

## Wire end ferrule

State: 2026-01-22 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.738 - Wire end ferrule Loose

With plastic collar.

## Features

Model No.	AS 4050.738
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	Gray
Length	12 mm
AWG	18
Internal diameter	2.8 mm
For cross section	0.75 mm <sup>2</sup>
DIN color code	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Suitable for Model No.	4051.205 4051.210
Delivery form	Loose (10 packs of 100)
Packaging unit	1,000 pc(s).
Net weight	1
Gross weight	1
Customs tariff number	85369010
EAN	4028177805064
ETIM 9	EC000005

# Features

---

ETIM 8 EC000005

---

ECLASS 8.0 36659290

# Approvals

---

Approvals UL + C-UL (listed)  
UR