


# Rittal – The System.

Faster – better – everywhere.

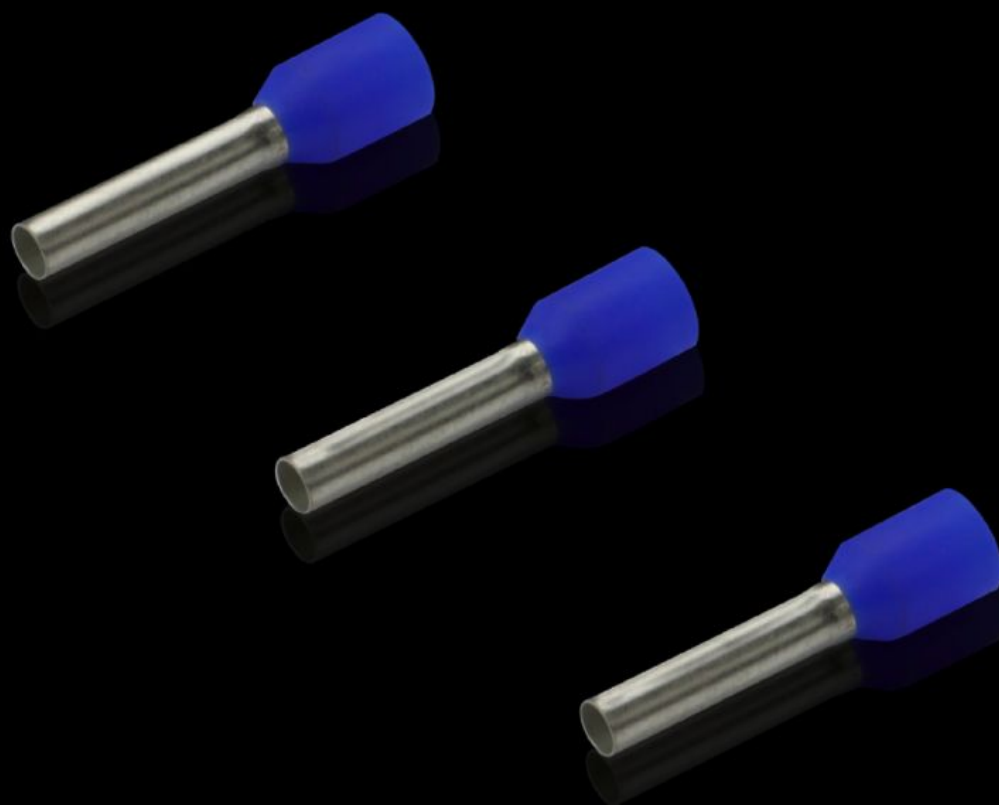

## AS 4050.741 Wire end ferrule

State: 2025-07-14 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.741 - Wire end ferrule Loose

With plastic collar.

## Features

Model No.	AS 4050.741
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	Blue
Length	12 mm
AWG	14
Internal diameter	4.2 mm
For cross section	2.5 mm <sup>2</sup>
DIN color code	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Suitable for Model No.	4051.205 4051.210
Delivery form	Loose (10 packs of 100)
Packaging unit	1,000 pc(s).
Gross weight	6
Customs tariff number	85369010
EAN	4028177805095
ETIM 9	EC000005
ETIM 8	EC000005

# Features

---

ECLASS 8.0	36659290
------------	----------

# Approvals

---

Approvals	UL + C-UL (listed) UR
-----------	--------------------------