


# Rittal – The System.

Faster – better – everywhere.

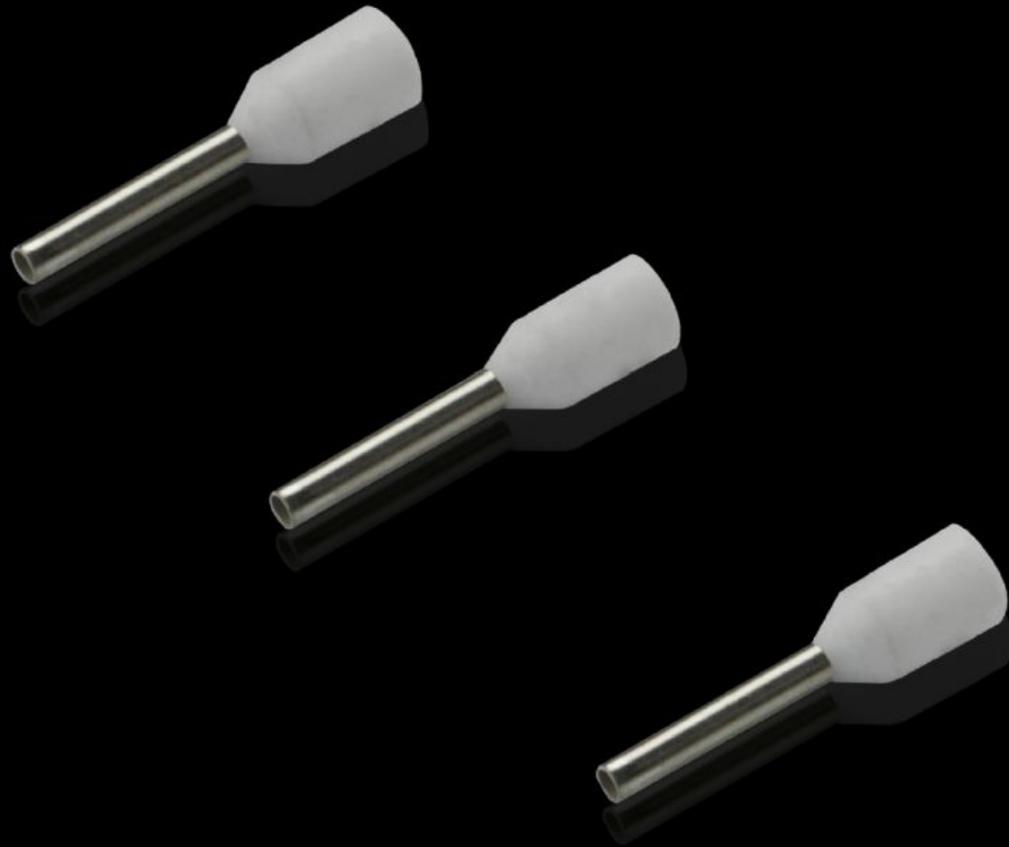

## AS 4050.742 Wire end ferrule

State: 2026-05-07 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.742 - Wire end ferrule Loose

With plastic collar.

## Features

Model No.	AS 4050.742
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	White
Length	8 mm
AWG	20
Internal diameter	2.9 mm
For cross section	0.5 mm <sup>2</sup>
DIN color code	Yes
Multinorm	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Delivery form	Loose
Packaging unit	500 pc(s).
Net weight	0.5 kg
Gross weight	0.5 kg
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290

# Features

---

Product description

Wire end ferrules for wire assembly, 0.5 mm<sup>2</sup>, AWG 20, white, loose, 8 mm (wide shaft)

# Approvals

---

Approvals

UL + C-UL (listed)  
UR