


Rittal – The System.

Faster – better – everywhere.

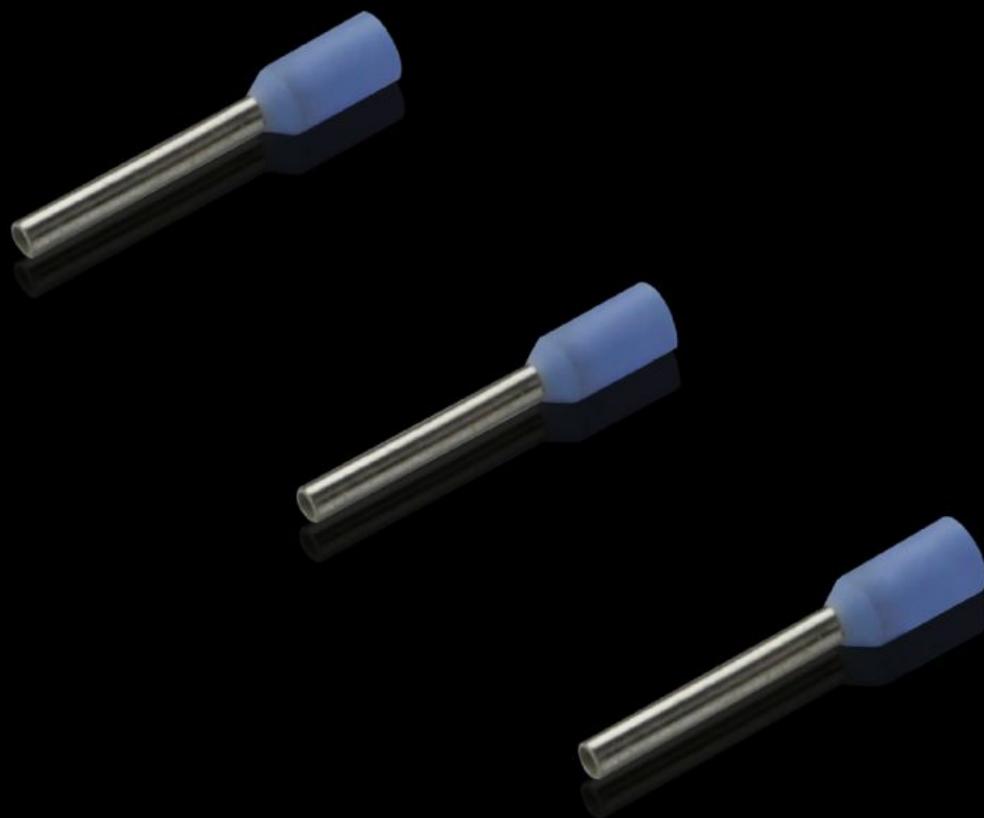

AS 4050.754

Wire end ferrule

State: 2026-01-16 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))

AS 4050.754 - Wire end ferrule Loose

With plastic collar.

Features

Model No.	AS 4050.754
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	Light blue
Length	8 mm
AWG	24
Internal diameter	1.8 mm
Rittal color code	Yes
For cross section	0.25 mm ²
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Delivery form	Loose
Packaging unit	500 pc(s).
Net weight	0.5
Gross weight	0.026
Customs tariff number	85369010
EAN	4028177815803
ETIM 9	EC000005
ETIM 8	EC000005

Features

ECLASS 8.0 36659290

Approvals

Approvals UL + C-UL (listed)
UR