


# Rittal – The System.

Faster – better – everywhere.

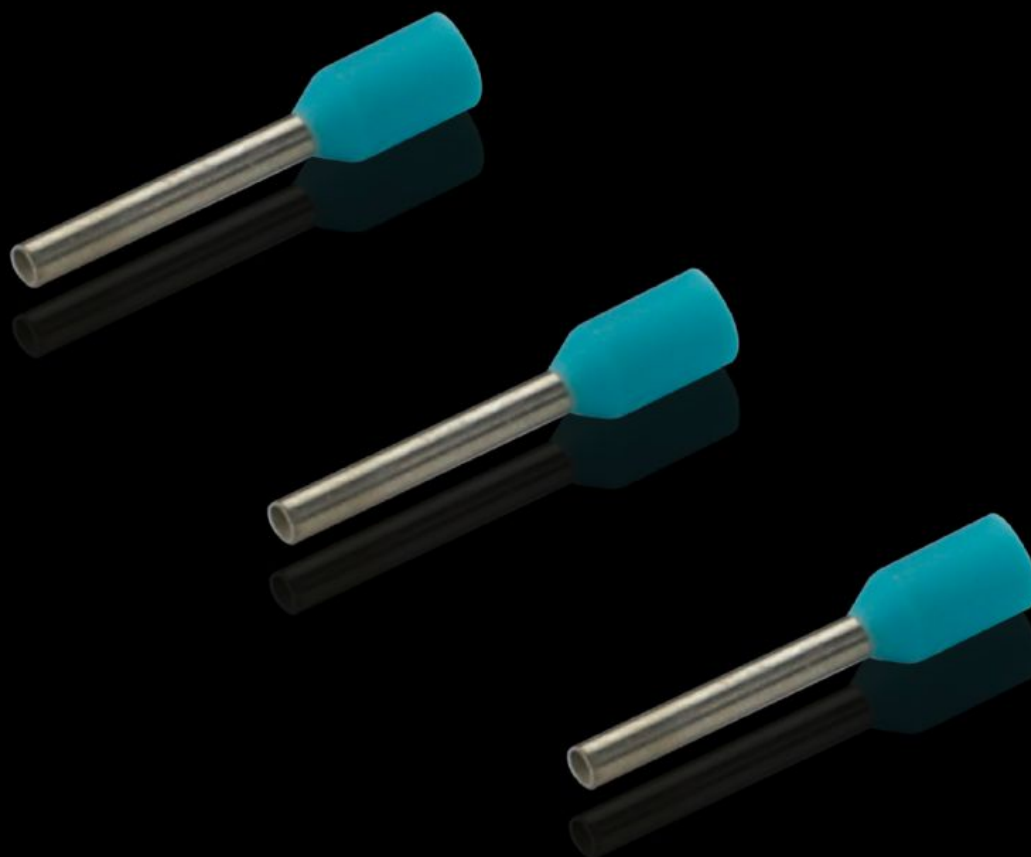

## AS 4050.757 Wire end ferrule

State: 2025-12-16 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.757 - Wire end ferrule Loose

With plastic collar.

## Features

Model No.	AS 4050.757
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	Turquoise
Length	8 mm
AWG	22
Internal diameter	2 mm
Rittal color code	Yes
For cross section	0.34 mm <sup>2</sup>
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Delivery form	Loose
Packaging unit	500 pc(s).
Net weight	0.5
Gross weight	0.026
Customs tariff number	85369010
EAN	4028177815797
ETIM 9	EC000005
ETIM 8	EC000005

# Features

---

ECLASS 8.0	36659290
------------	----------

# Approvals

---

Approvals	UL + C-UL (listed) UR
-----------	--------------------------