


Rittal – The System.

Faster – better – everywhere.

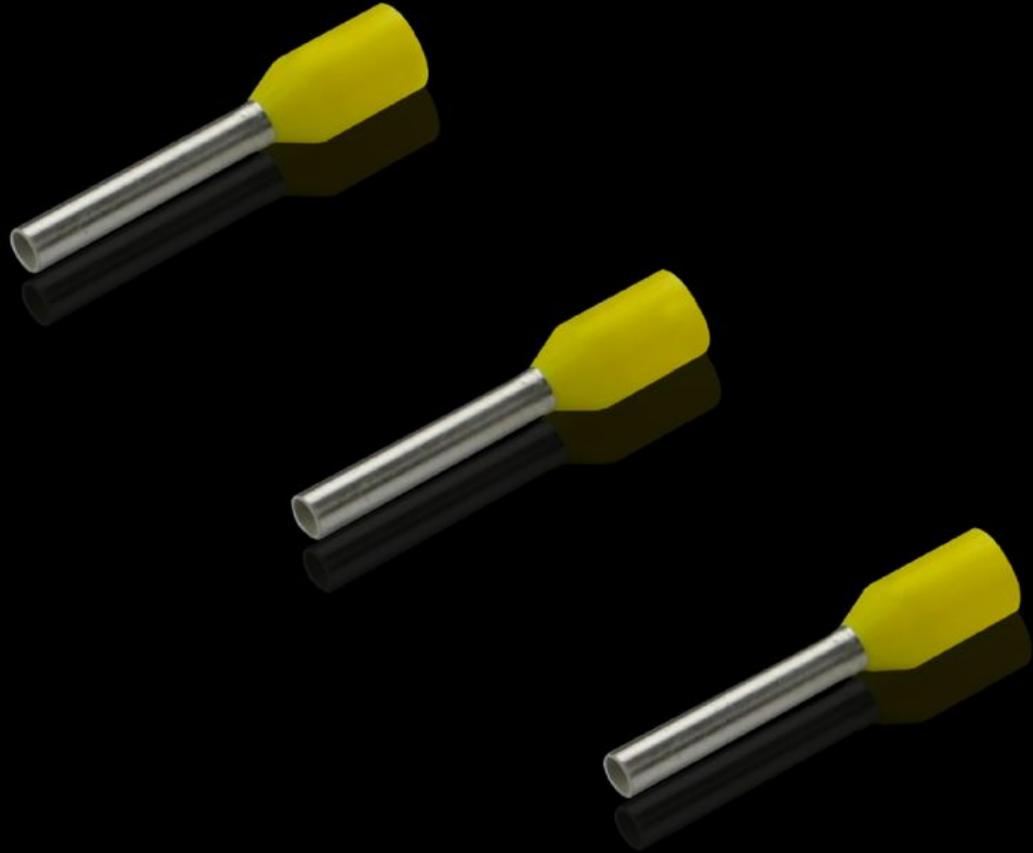

AS 4050.770 Wire end ferrule

State: 2026-05-10 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.770 - Wire end ferrule Loose

With plastic collar.

Features

Model No.	AS 4050.770
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	Yellow
Length	10 mm
AWG	18
Internal diameter	3 mm
Rittal color code	Yes
For cross section	1 mm ²
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Suitable for Model No.	4051.205 4051.210
Delivery form	Loose
Packaging unit	500 pc(s).
Net weight	0.5 kg
Gross weight	0.058 kg
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005

Features

ECLASS 8.0	36659290
Product description	Wire end ferrules for wire assembly, 1 mm ² , AWG 18, 10 mm, yellow, loose, 500 pieces

Approvals

Approvals	UL + C-UL (listed) UR
-----------	--------------------------