


Rittal – The System.

Faster – better – everywhere.

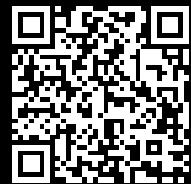

AS 4051.105

Working light LED

State: 2026-02-13 (Source: rittal.com/ca-en)

AS 4051.105 - Working light LED for WS 540

For attachment to the table top, with clamping device.



Features

Model No.	AS 4051.105
Product description	For attachment to the table top, with clamping device.
Benefits	<p>High-intensity, glare and flicker-free lighting, homogeneous and shadow-free</p> <p>Selectable color temperature between warm white, neutral white and daylight white promotes concentration and reduces fatigue</p> <p>Excellent color fidelity and strong contrast</p> <p>Aluminum spring arm with 3D head joint, swiveling and lockable for free positioning of light source</p>
Technical specifications	<p>Spring arm: length 970 mm</p> <p>Color rendering: 94–98 Ra</p> <p>Angle of projection: 100°</p>
Material	<p>Light enclosure: aluminum</p> <p>Glare reduction: Macrolon</p>
Supply includes	<p>Working light LED</p> <p>Assembly components</p>
Rated power	26 W
Length of connection cable	3 m
Connection options	Plug-in power supply unit (CEE 7/16) with AC adapter
Light (bulb)	84 SMD LEDs
Protection category	III (SELV)

Features

Luminous flux	2,930 lm
Suitable for Model No.	4051.100
Operating temperature range	-10 °C...40 °C
Rated operating voltage	110 V - 240 V, 1~, 50 Hz/60 Hz
Dimensions	Width: 545 mm Height: 90 mm Depth: 35 mm
Packaging unit	1 pc(s).
Net weight	2.5
Gross weight	4.2
Customs tariff number	94054990
EAN	4028177957466
ETIM 9	EC002778
ETIM 8	EC002778
ECLASS 8.0	36629090