


# Rittal – The System.

Faster – better – everywhere.

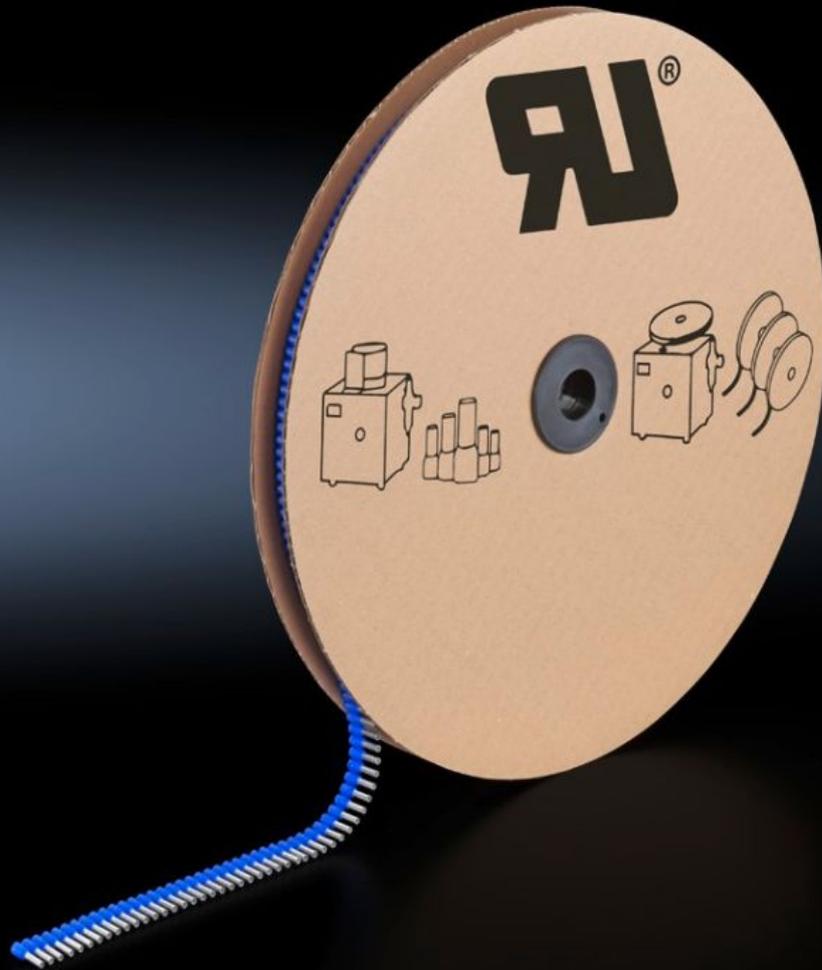

## AS 4051.605 Wire end ferrule

State: 2026-05-08 (Source: [rittal.com/ca-en](http://rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4051.605 - Wire end ferrule on belt

With plastic flange.

## Features

|                          |   |
|--------------------------|---|
| Model No.                | AS 4051.605   |
| Product description      | With plastic flange.  |
| Technical specifications | Heat resistant up to 105 °C   |
| Material                 | E-Cu, tin-plated<br>Plastic collar: Polypropylene   |
| Color                    | Blue  |
| Length                   | 10 mm   |
| AWG                      | 14  |
| Internal diameter        | 4.2 mm  |
| For cross section        | 2.5 mm <sup>2</sup>   |
| DIN color code           | Yes   |
| Note                     | UL-certified in conjunction with the relevant tools, e.g. crimping machines.  |
| Standards                | AEH DIN 46228   |
| Delivery form            | Taped   |
| Packaging unit           | 3,000 pc(s).  |
| Net weight               | 3 kg  |
| Customs tariff number    | 85369010  |
| ETIM 9                   | EC000005  |
| ETIM 8                   | EC000005  |
| ECLASS 8.0               | 36659290  |
| Product description      | Wire end ferrules 2.5 mm <sup>2</sup> x 10 mm AWG 14, packs of 3,000 pc(s)., colour: blue, delivery form: on belt (in accordance with the DIN/Rittal colour code) |

# Approvals

---

Approvals

UL + C-UL (listed)