


**Rittal – The System.**

Faster – better – everywhere.

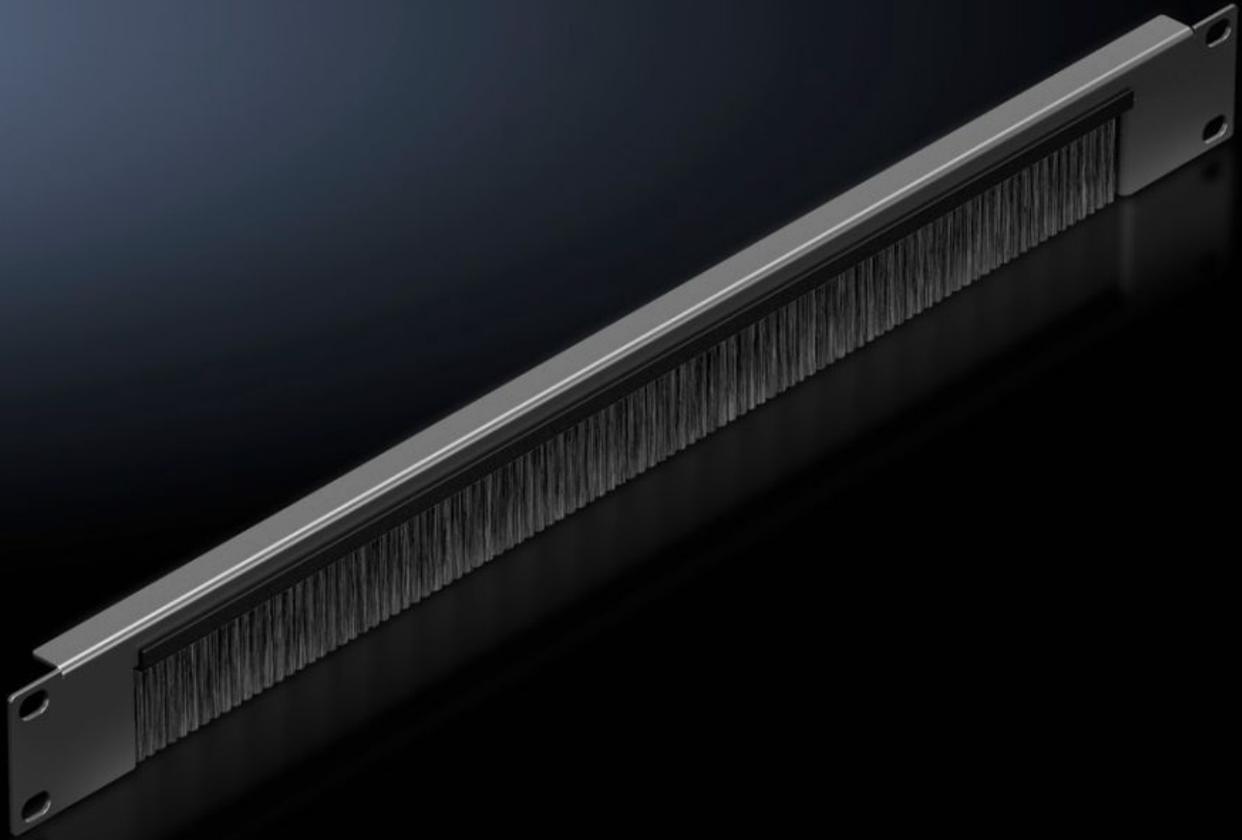

**DK 5302.202**

**Cable entry panel with brush strip**

State: 2026-06-10 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 5302.202 - Cable entry panel with brush strip

## 482.6 mm (19")

With cut-out 390 x 60 mm when using two opposite panels (2 U) or 390 x 30 mm for one panel (1 U) with brush insert.



## Features

Model No.	DK 5302.202
Product description	For convenient, simple cable routing between two areas separated by an imperial mounting level, e.g. between the front and rear areas of the 19" mounting level.
Benefits	Two panels can simply be combined with one another to make the cable gland bigger
Applications	For locking and simultaneous cable routing in installation zones to the 1 U, 482.6 mm (19") mounting standard
Material	Carbon steel Brush strip: Plastic, UL 94-HB, halogen-free Brush strip fibers: plastic PA6, halogen-free Fixing body brush strip: plastic PVC, halogenated
Surface finish	Spray-finished
Color	RAL 9005
Mounting cut-out	Width:390 mm Height:30 mm
Dimensions	Width: 482.6 mm
Height units	1 U

# Features

Packaging unit	1 pc(s).
Net weight	0.2 kg
Gross weight	0.243 kg
PCF/VE (cradle-to-gate)	0.9 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73269098
ETIM 9	EC000322
ECLASS 8.0	27400604
Product description	Cable gland panel with brush strip, 1 U, 482.6 mm (19"), sheet steel, RAL 9005