


Rittal – The System.

Faster – better – everywhere.

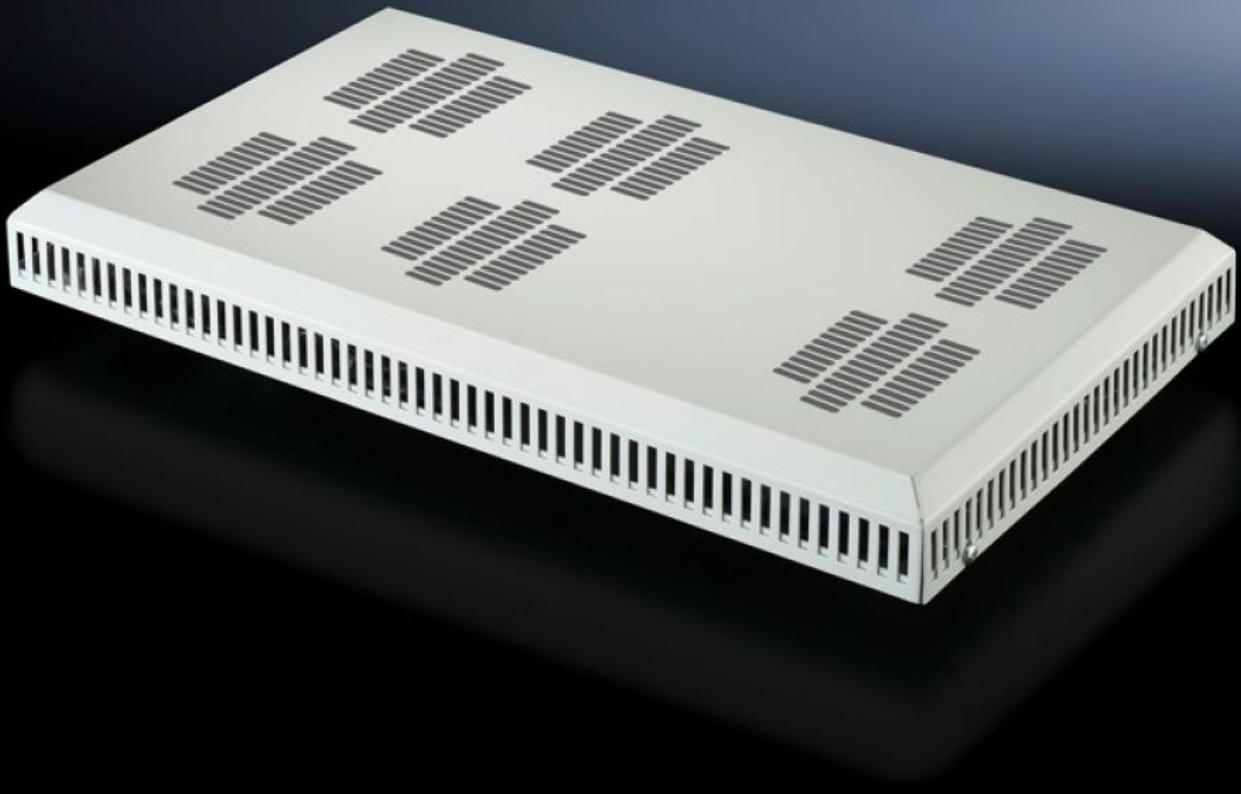

DK 5502.010

Fan tray

State: 2026-04-11 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 5502.010 - Fan tray for VX IT, TS IT, TX CableNet

For active ventilation of the VX IT, TS IT, or TE 8000, depending on the version.

Features

Model No.	DK 5502.010
Product description	For active ventilation. The unit may optionally be extended with additional fans.
Applications	For use in the cut-out integrated into the roof plate
Color	RAL 7035
Supply includes	1 fan unit 2 fans 1 thermostat Connection cable, open-end Assembly components
Air throughput per fan (unimpeded air flow)	160/180
Rated operating voltage	230 V, 1~, 50 Hz/60 Hz
Dimensions	Width: 200 mm Height: 59 mm Depth: 550 mm
Air throughput of fans (unimpeded air flow)	1514
Installation options	In the VX IT with W x D (mm): 600 x 600/600 x 800/600 x 1000/600 x 1200/800 x 600 In TS IT with W x D: 600 x 600 / 600 x 800 / 600 x 1000 / 600 x 1200 / 800 x 600
Note	The specified sound level relates to the first fan Connection via distributor box or country-specific connector
Sound pressure level per fan	37 dB(A)
Suitable for	Enclosure type: VX IT TS IT TX CableNet

Features

Operating temperature range	5 °C...55 °C
Packaging unit	1 pc(s).
Net weight	3.027 kg
Gross weight	3.3 kg
Customs tariff number	84149000
ECLASS 8.0	27189272
Product description	DK fan mounting plate, for use in roof plate, incl. 2 fans, expandable to max. 3 fans, WHD: 200x59x550 mm

Approvals

Explanations	Declaration of conformity UK
--------------	------------------------------