


Rittal – The System.

Faster – better – everywhere.

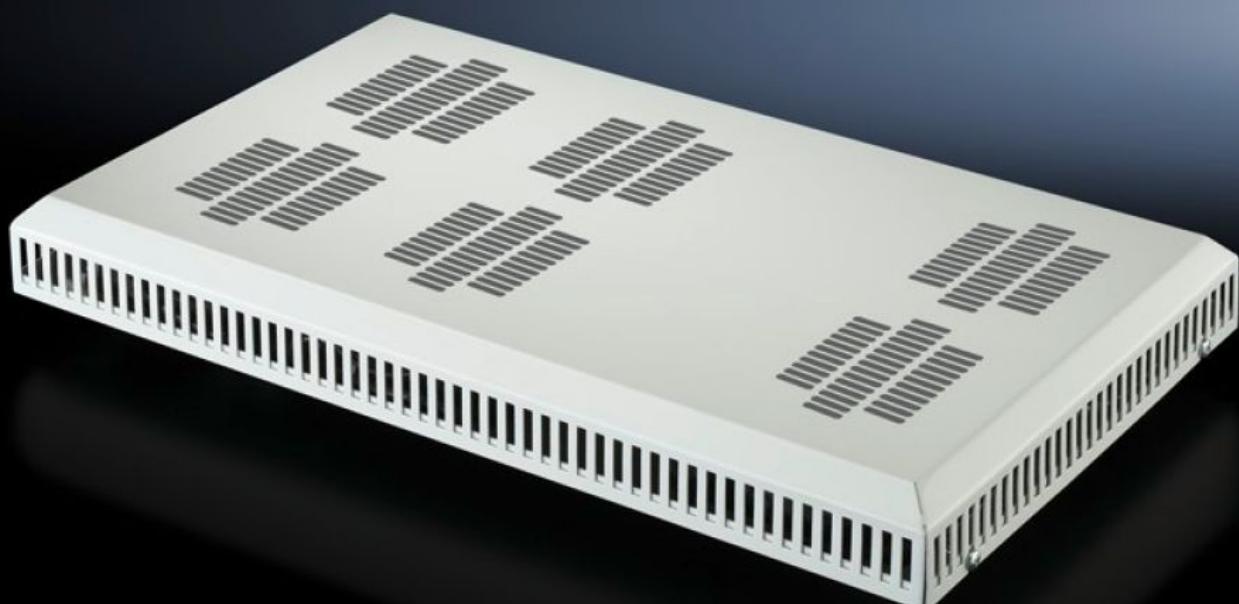

DK 5502.010

Fan tray

State: 2026-02-01 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 5502.010 - Fan tray for VX IT, TS IT, TX CableNet

For active ventilation of the VX IT, TS IT, or TE 8000, depending on the version.

Features

| | |
|---|---|
| Model No. | DK 5502.010 |
| Product description | For active ventilation. The unit may optionally be extended with additional fans. |
| Applications | For use in the cut-out integrated into the roof plate |
| Color | RAL 7035 |
| Supply includes | 1 fan unit 2 fans 1 thermostat Connection cable, open-end Assembly components |
| Air throughput per fan (unimpeded air flow) | 160/180 |
| Rated operating voltage | 230 V, 1~, 50 Hz/60 Hz |
| Dimensions | Width: 200 mm Height: 59 mm Depth: 550 mm |
| Air throughput of fans (unimpeded air flow) | 1514 |
| Installation options | In the VX IT with W x D (mm): 600 x 600/600 x 800/600 x 1000/600 x 1200/800 x 600 In TS IT with W x D: 600 x 600 / 600 x 800 / 600 x 1000 / 600 x 1200 / 800 x 600 |
| Note | The specified sound level relates to the first fan Connection via distributor box or country-specific connector |
| Sound pressure level per fan | 37 dB(A) |
| Suitable for | Enclosure type: VX IT TS IT TX CableNet |

Features

Operating temperature range 5 °C...55 °C

Packaging unit 1 pc(s).

Net weight 3.027

Gross weight 3.3

Customs tariff number 84149000

EAN 4028177679245

ECLASS 8.0 27189272

Approvals

Explanations Declaration of conformity UK