


**Rittal – The System.**

Faster – better – everywhere.

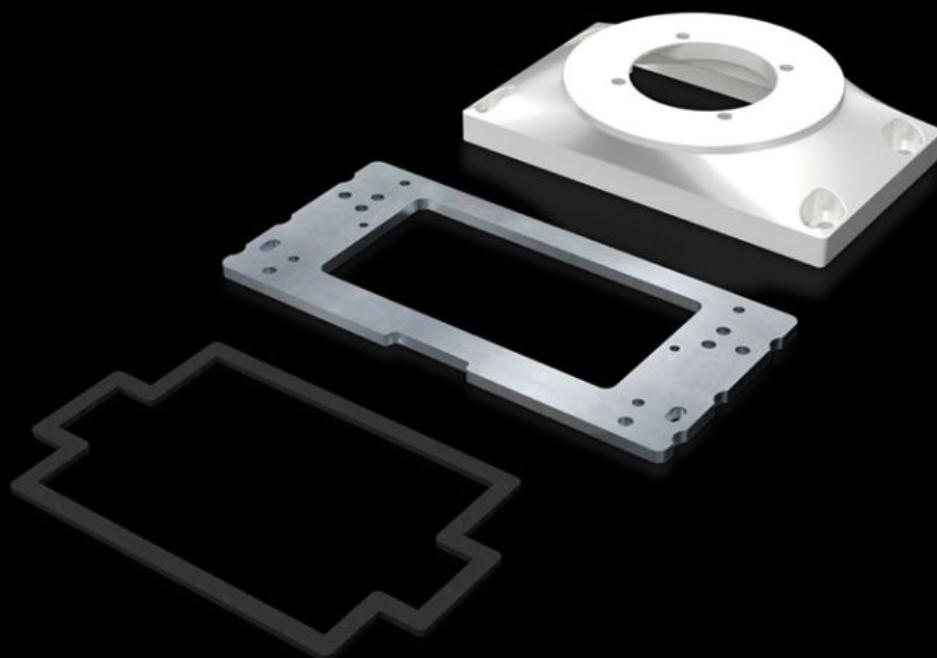

# CP 6212.540

## Connection Plate

State: 2026-01-21 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



FRIEDHELM LOH GROUP

# CP 6212.540 - Connection Plate with reinforcement plate

For easy location of the command panel onto the support arm or pedestal.

## Features

Model No.	CP 6212.540
Version	<p>For mounting</p> <p>Comfort Panel from a front panel width of 247 mm and installation depth of 152 mm</p> <p>Optipanel from a front panel width of 220 mm and installation depth of 150 mm</p> <p>Carbon steel from 135 mm installation depth</p> <p>For mounting on support arm system components</p> <p>Attachment CP 60/120 for support arm connection Ø 130 mm, 6206.320, 6212.320</p> <p>Coupling CP 60/120/180 for support arm connection Ø 130 mm, 6206.300, 6212.300, 6218.300</p> <p>Angle coupling 90° CP 60/120 for support arm connection Ø 130 mm, CP 6206.380, 6212.380</p> <p>Tilting adapter 10°, system 60/120 for support arm connection Ø 130 mm, CP 6206.400</p> <p>Tilting adapter ±45°, 60/120 for support arm connection Ø 130 mm, CP 6206.420</p>
Benefits	<p>For easy location of the command panel onto the support arm or pedestal.</p> <p>More space for cable entry</p>
Material	<p>Connection plate: Cast aluminum</p> <p>Reinforcement plate: Carbon steel, 6 mm</p>
Color	RAL 7035
Supply includes	<p>Reinforcement plate</p> <p>Seals</p> <p>Fasteners</p>
Packaging unit	1 pc(s).
Net weight	1.3
Gross weight	1.604

## Features

---

Customs tariff number 76169990

EAN 4028177684232

ETIM 9 EC000882

ECLASS 8.0 27400556

## Approvals

---

Explanations

Manufacturer's declaration