

Rittal – The System.

Faster – better – everywhere.



CX 6740.000

CX One-Piece Console

State: 2026-02-04 (Source: rittal.com/ca-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



CX 6740.000 - CX One-Piece Console

One-piece console for operating and monitoring, with large mounting plate and a high protection category of IP 55, available in four different widths.

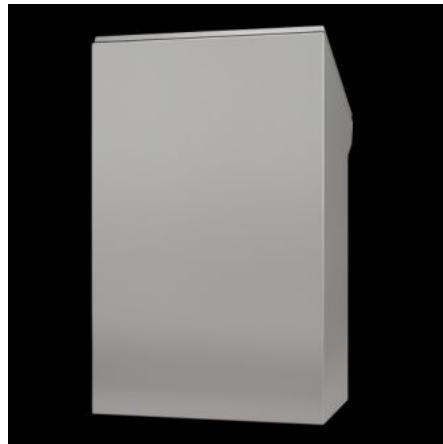

Features

Model No.	CX 6740.000
Version	One-piece consoles
Material	Housing: Carbon steel, 1.5 mm Door and console lid: Carbon steel, 2.0 mm, all-round foamed-in PU seal Mounting plate: Carbon steel, 2.5 mm
Surface finish	Housing, cover and door: Dipcoat-primed, powder-coated on the outside, textured paint Mounting panel: Zinc-plated
Color	RAL 7035
Supply includes	Housing, solid back and sides Door or double door at front, with 3-point locking system Mounting panel Cover with cam locks, hinged at rear, 2 stays with automatic locking. Unlocking automatically on the left, manually on the right. Gland plate Lock: 3 mm double-bit
Dimensions	Width: 1,000 mm Height: 970 mm Depth: 400 mm

Features

Dimensions of mounting plate (W x H) 920 mm x 900 mm

Top depth 495 mm

Bottom depth 400 mm

Number of doors 2

IK code IK10

Protection category IP to IEC 60529 IP 55

Protection category NEMA NEMA 1
NEMA 12

Base material Carbon steel

Dimensions Width: 1,000 mm
Height: 970 mm
Top depth: 495 mm
Bottom depth: 400 mm

Packaging unit 1 pc(s).

Net weight 72

Gross weight 75.25

Customs tariff number 94032080

EAN 4028177983632

ETIM 9 EC000784

ETIM 8 EC000784

ECCLASS 8.0 27180504

Approvals

Approvals UL + C-UL (listed)

Explanations Declaration of conformity