


Rittal – The System.

Faster – better – everywhere.

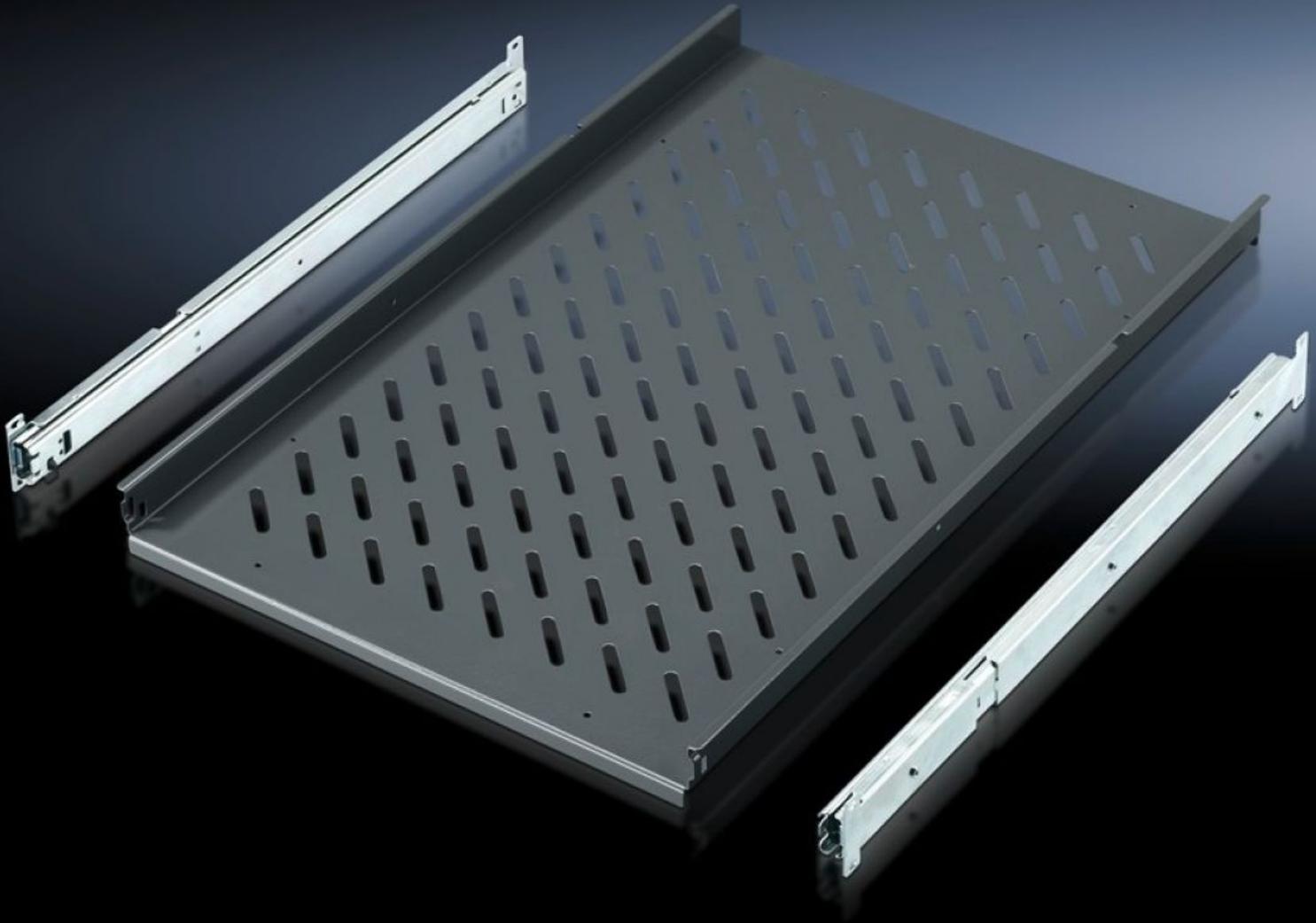

IW 6902.960

Component shelf, pull-out

State: 2026-05-05 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



IW 6902.960 - Component shelf, pull-out for TS, PC, IW

Mounted directly on the vertical TS enclosure profile, enclosure width.

Features

Model No.	IW 6902.960
Material	Carbon steel
Color	RAL 7015
Supply includes	2 telescopic slides.
Load capacity	30 kg surface load, static
Note	For enclosures without a mounting plate
Note on Model No.:	May also be installed in 800 mm deep enclosures based on TS (pull-out rear attachment).
Support area	Width: 465 mm Depth: 545 mm
Suitable for	Enclosure type: TS PC IW Width: = 600 mm Depth: = 600 mm = 800 mm
Packaging unit	1 pc(s).
Net weight	6.854 kg
Gross weight	7.215 kg
PCF/VE (cradle-to-gate)	29.7 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	94039910
ETIM 9	EC002620
ECLASS 8.0	27189261

Features

Product description

IW component shelf, pull-out, for TS, PC, IW, for enclosure depth 600 mm