


Rittal – The System.

Faster – better – everywhere.

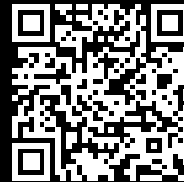

DK 7000.625

Component shelf, pull-out

State: 2025-12-24 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7000.625 - Component shelf, pull-out for TE

Complete kit consisting of vented component shelves, telescopic rails and a mounting kit for direct attachment, depth-variable mounting possible, load capacity: 50 kg.

Features

Model No.	DK 7000.625
Product description	Mounted between two 19" mounting levels.
Benefits	Depth-variable for adjusting to 19" levels in 25 mm hole pattern Full withdrawal
Material	Base: Carbon steel
Surface finish	Base: Spray-finished Mounting kit/telescopic slides: Zinc-plated
Color	RAL 7035
Supply includes	Component shelf, vented Telescopic slides with mounting kit
Load capacity static	500 N
Contact surface	Width: 409 mm Depth: 500 mm
Dimensions	Width: 482.6 mm Depth: 500 mm
Distance between levels	395 - 645 mm
Packaging unit	1 pc(s).
Net weight	4.577
Gross weight	4.777
Customs tariff number	94039910
EAN	4028177553149
E-Number Sweden	E7282515
ETIM 9	EC002620

Features

ECLASS 8.0

27189261