


Rittal – The System.

Faster – better – everywhere.

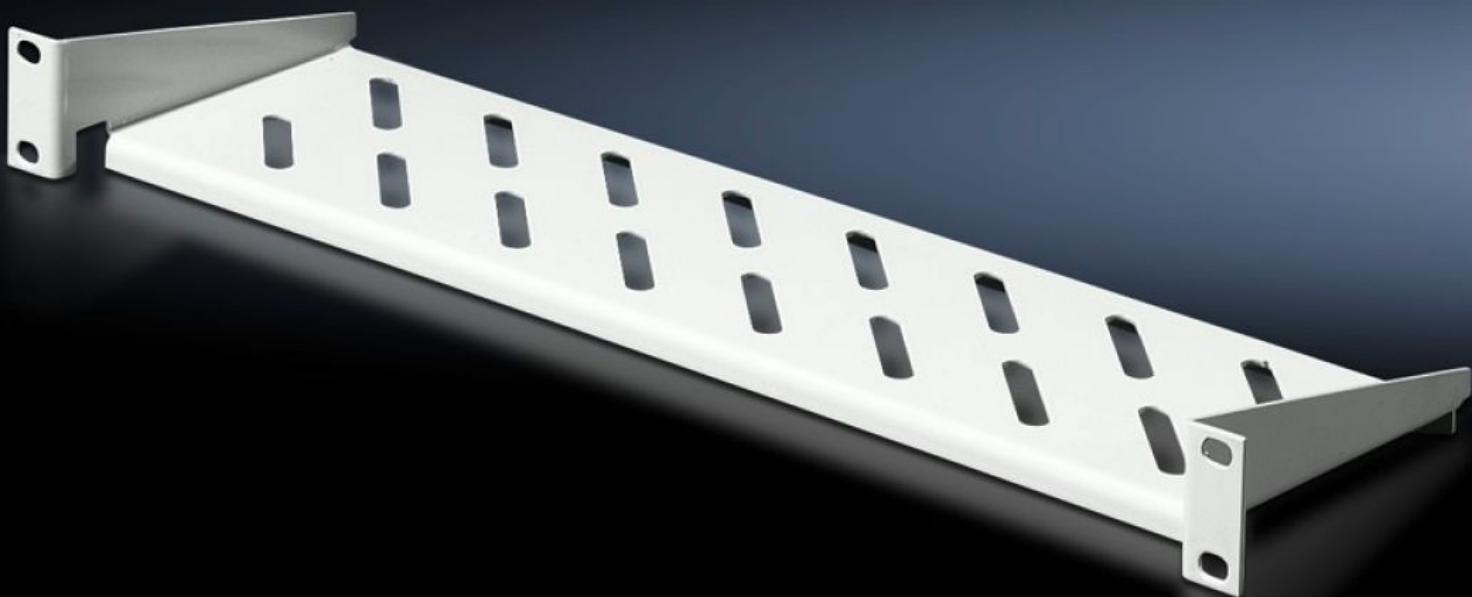

DK 7119.140

**Component Shelf 1 U, Static
Installation**

State: 2026-01-31 (Source: rittal.com/ca-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL



IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

DK 7119.140 - Component Shelf 1 U, Static Installation 482.6 mm (19") system punchings

482.6 mm (19")/535 mm (metric), support surface for small active components such as modems or mini-hubs in 19" or metric levels: 10 kg.

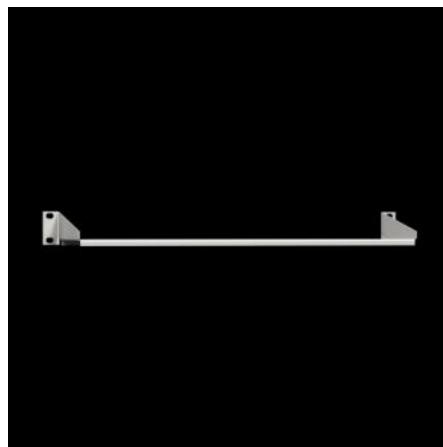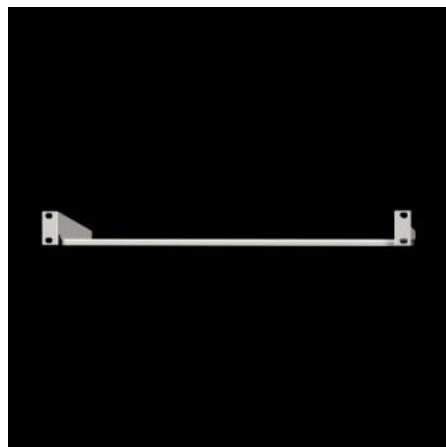

Features

Model No.	DK 7119.140
Version	482.6 mm (19") version
Product description	The ideal support surface for small active components such as modems or mini-hubs.
Material	Carbon steel
Color	RAL 7035
Load capacity	10 kg surface load, static
Note	Not suitable for combination with telescopic slides. Free installation height inside the U approx. 35 mm
Dimensions	Width: 482.6 mm Depth: 140 mm
Packaging unit	1 pc(s).
Net weight	0.781
Gross weight	0.881
PCF/VE (cradle-to-gate)	3.2 kg CO ₂ eq (Cat B)

Features

Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	94039910
EAN	4028177221444
ETIM 9	EC002620
ECLASS 8.0	27189261