


Rittal – The System.

Faster – better – everywhere.

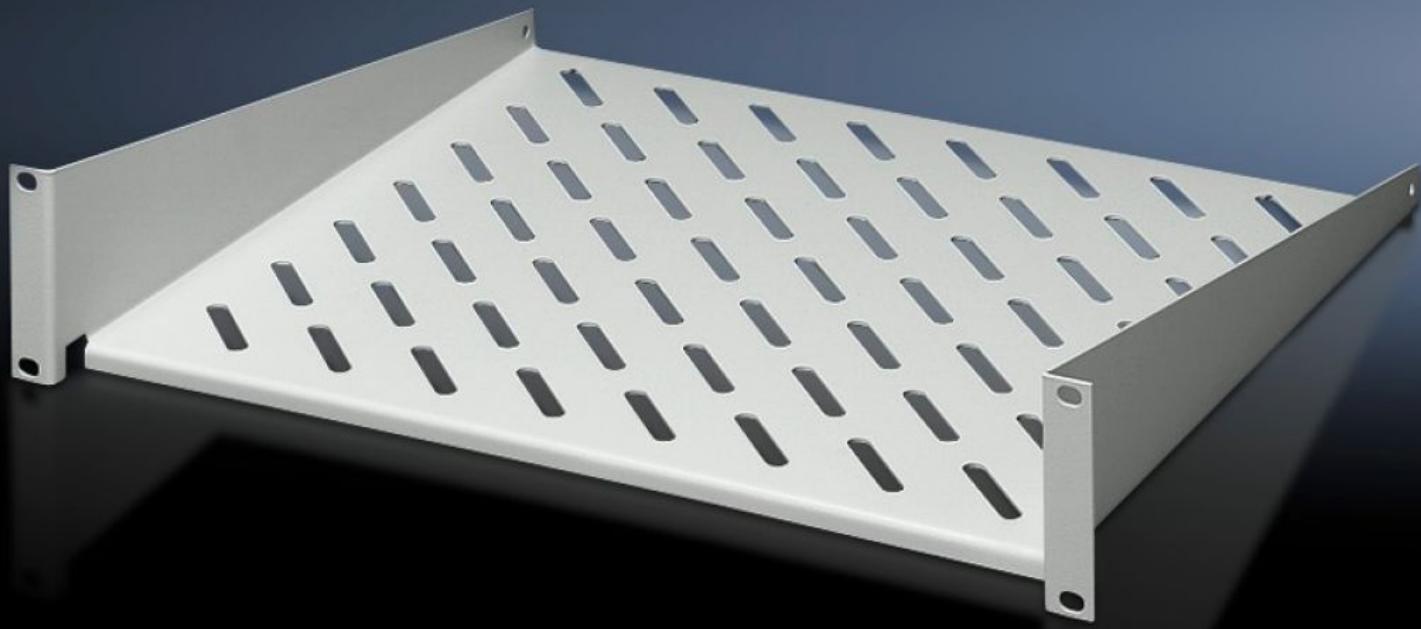

DK 7119.250

**Component Shelf 2 U, Static
Installation**

State: 2026-02-07 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL




IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

DK 7119.250 - Component Shelf 2 U, Static Installation

Component shelves 2 U, fixed, for attachment to 19" system punchings. Load capacity: 25 kg.

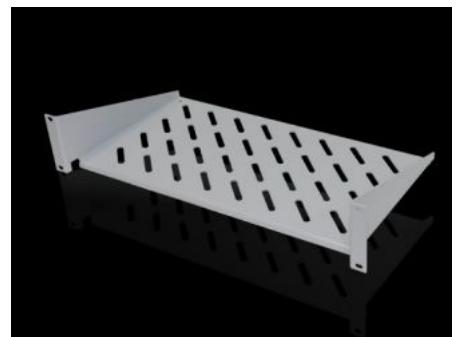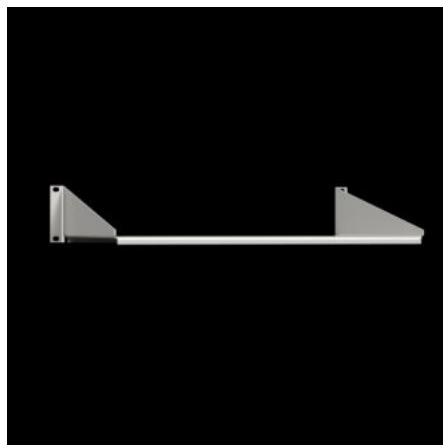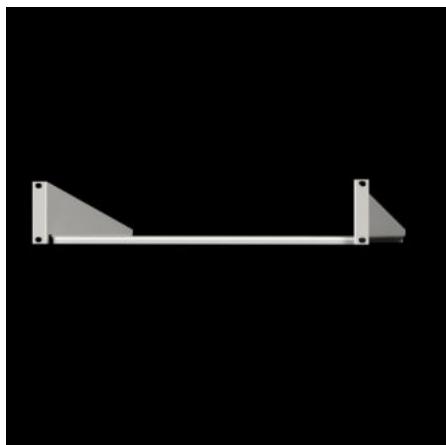

Features

Model No.	DK 7119.250
Version	19"
Product description	Mounted on vertical 482.6 mm (19") rails.
Material	Carbon steel
Surface finish	Spray-finished
Color	RAL 7035
Load capacity	25 kg surface load, static
Note	Not suitable for combination with telescopic slides.
Dimensions	Width: 482.6 mm Depth: 250 mm
Packaging unit	1 pc(s).
Net weight	1.92
Gross weight	2.28
PCF/VE (cradle-to-gate)	9 kg CO ₂ eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared

Features

Customs tariff number 94039910

EAN 4028177187207

ETIM 9 EC002620

ECLASS 8.0 27189261