

**Rittal – The System.**

Faster – better – everywhere.



**DK 7119.400**

**Component Shelf 2 U, Static  
Installation**

State: 2025-08-04 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7119.400 - Component Shelf 2 U, Static Installation

Component shelves 2 U, fixed, for attachment to 19" system punchings. Load capacity: 25 kg.

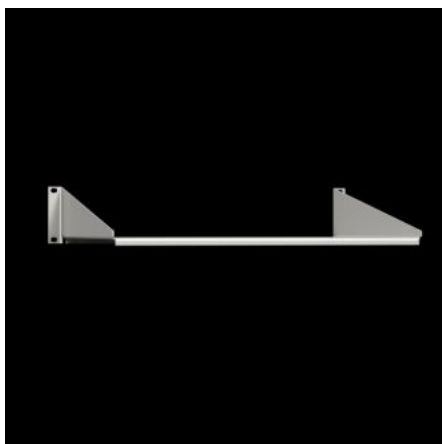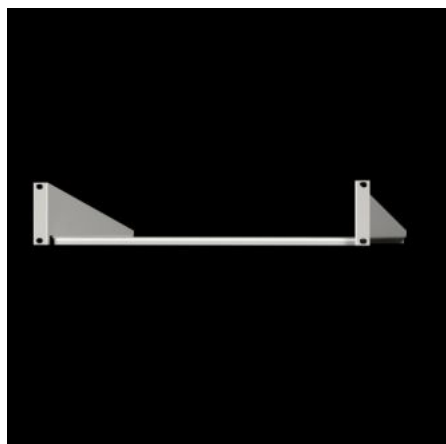

## Features

Model No.	DK 7119.400
Version	19"
Product description	Mounted on vertical 482.6 mm (19") rails.
Material	Carbon steel
Surface finish	Spray-finished
Color	RAL 7035
Load capacity	25 kg surface load, static
Note	Not suitable for combination with telescopic slides.
Dimensions	Width: 482.6 mm Depth: 400 mm
Packaging unit	1 pc(s).
Net weight	3.19
Gross weight	3.58
PCF/VE (cradle-to-gate)	12.9 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared

# Features

Customs tariff number	94039910
EAN	4028177187214
ETIM 9	EC002620
ECLASS 8.0	27189261