

Rittal – The System.

Faster – better – everywhere.



DK 7299.000


Second Mounting Level

State: 2026-02-01 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



DK 7299.000 - Second Mounting Level for Data Rack

To accommodate 482.6 mm (19") network components or to mount component shelves and slide rails.

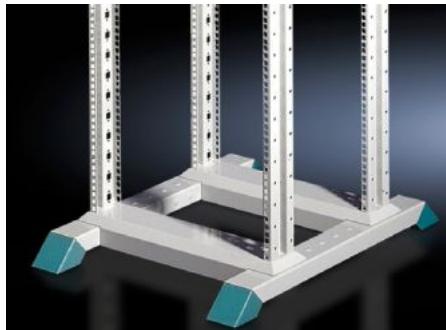

Features

Model No.	DK 7299.000
Product description	To accommodate 482.6 mm (19") network components or to mount component shelves and slide rails. 482.6 mm (19") profiles holes at the front, hole center-to-center spacing 465 mm, rear 470 mm, designed for the attachment of patch panels and cable routing rails. The mounting level can be positioned in the 50 mm hole pattern. Minimum clearance between levels 150 mm, maximum clearance between levels 350 mm.
Material	Carbon steel, 2 mm
Surface finish	Spray-finished
Color	Profile frame: RAL 7035 Trim Panel: RAL 5018
Supply includes	Torsionally rigid profile frame with 482.6 mm (19") holes Mounting Accessories
Installation dimensions	Installation depth for components: 482.6 mm Installation width for components: 19"
Height units	45 U
Packaging unit	1 pc(s).
Net weight	13.899
Gross weight	14.63

Features

PCF/VE (cradle-to-gate)	55.7 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	94039910
EAN	4028177128859
E-Number Sweden	E7282523
ETIM 9	EC002620
ECLASS 8.0	27189261