


Rittal – The System.

Faster – better – everywhere.

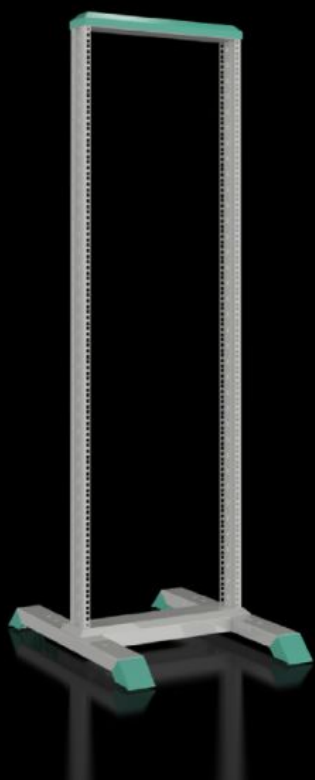

DK 7396.000

Distributor Racks

State: 2024-04-27 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7396.000 - Distributor Racks Data Rack

Data Rack for optimum accessibility from all sides during assembly and installation, and a high degree of mobility when twin castors are used.



Features

Model No.	DK 7396.000
Material	Profile frame, base/plinth: Carbon steel Feet: Die-cast zinc
Color	Profile frame, base/plinth: RAL 7035 Panel, feet: RAL 5018
Supply includes	Torsionally rigid profile frame with 482.6 mm (19") holes Stable base/plinth with integral feet, with the option of floor anchoring without base trim panels Mounting Accessories
Dimensions	Width: 550 mm Height: 1,722 mm Depth: 750 mm
Height units	36 U
Distance from the second mounting level, 50 mm hole pattern	150 - 350 mm
Hole pattern between the mounting levels	50 mm
Load capacity of the 19" levels	1,500 N
Note	Order second mounting level separately

Features

Base material	Carbon steel
Packaging unit	1 pc(s).
Weight/packaging unit	18.65 kg
Customs tariff number	94032080
EAN	4028177129894
E-Number Sweden	E7239647
ETIM 7.0	EC002507
ECLASS 8.0	27180602