
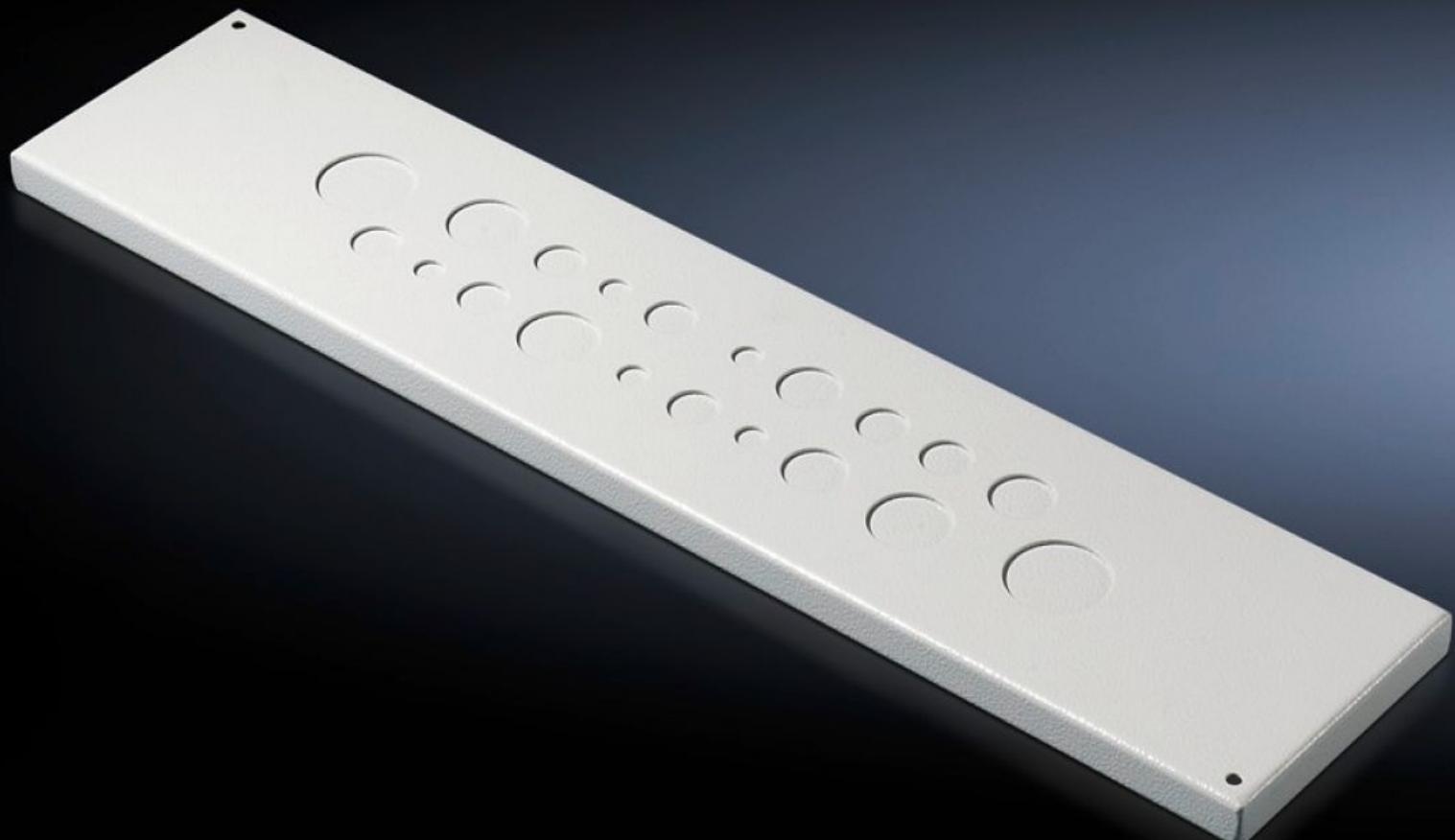


Rittal – The System.

Faster – better – everywhere.

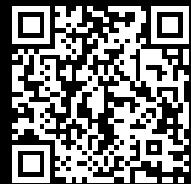

EL 7705.235

Gland plate for metric cable glands

State: 2026-02-10 (Source: rittal.com/ca-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

EL 7705.235 - Gland plate for metric cable glands for EL

Folded flange plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands.

Features

Model No.	EL 7705.235
Product description	Folded flange plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands M12, M20, M25, M32, M40.
Material	Carbon steel, 1.5 mm
Color	RAL 7035
No. of metric knockouts	4 x M12 8 x M20 6 x M25 1 x M32 1 x M40
Dimensions	Width: 599 mm Depth: 133.5 mm
Protection category IP to EN 60 529	IP 55
Number knockouts	4 8 6 1 1
Metric diameter	M12 M20 M25 M32 M40
Packaging unit	1 pc(s).
Net weight	1.55
Gross weight	1.64

Features

PCF/VE (cradle-to-gate)	6.2 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73079100
EAN	4028177389854
ETIM 9	EC000211
ECLASS 8.0	27142421
