


# Rittal – The System.

Faster – better – everywhere.

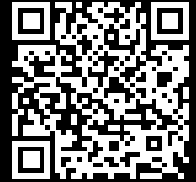

## DK 7721.535

# Wall-mounted enclosures EL, 3-part

State: 2026-04-05 (Source: [rittal.com/ca-en](http://rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7721.535 - Wall-mounted enclosures EL, 3-part pre-configured with profile rails, depth-variable

Wall-mounted housing 3-part, pre-configured with: Solid flange plate, top, with brush strip at the bottom, mounting rails, C rails, outlet filter, ground rail, wall-mounting bracket

## Features

Model No.	DK 7721.535
Version	Wall-mounted housing IT pre-configured with profile rails, depth-variable
Product description	Wall-mounted enclosure with hinged door provides optimum accessibility.
Material	Wall and hinged part: Carbon steel, 1.5 mm Viewing window: Single-pane safety glass, 3 mm
Surface finish	Powder-coated
General color	RAL 7035
Color	Wall and hinged part: RAL 7035 Viewing door: RAL 7035/7015 (slate gray)
Supply includes	Wall section with solid gland plate at the top and brush strip at the bottom, two vertical mounting rails and C rail, horizontal, for cable clamping Hinged part with 25 mm pitch pattern in the front and rear frame, two 482.6 mm (19") profile angles at the front, fully depth adjustable and side outlet filters on left and right Ground rail with star grounding Designer viewing door 1 enclosure key double bit no. 5 Wall mounting brackets, 10 mm, reinforced Comfort handle for lock inserts and 2-point locking Security lock 3524 E
Height units	21 U

# Features

---

Dimensions	Width: 600 mm Height: 1,012 mm Depth: 673 mm
Installation depth	620 mm
Clearances	Clearance width: 502 mm Clearance height: 949 mm
Depth hinged part	516 mm
Depth of wall section	135 mm
IK code	IK08
Load capacity of hinged part (static)	750 N
Base material	Carbon steel
Protection category IP to EN 60529	IP 54 in conjunction with solid gland plate top and bottom
Packaging unit	1 pc(s).
Net weight	57 kg
Gross weight	59 kg
Customs tariff number	94032080
ETIM 9	EC000261
ECLASS 8.0	27142408
Product description	DK wall-mounted enclosure, 3-part, WHD: 600x1,021x673 mm, 21 HE, pre-mounted, IP 54 with closed flange plate at top and bottom

# Approvals

---

Approvals	UL + C-UL (listed)
-----------	--------------------