


# Rittal – The System.

Faster – better – everywhere.

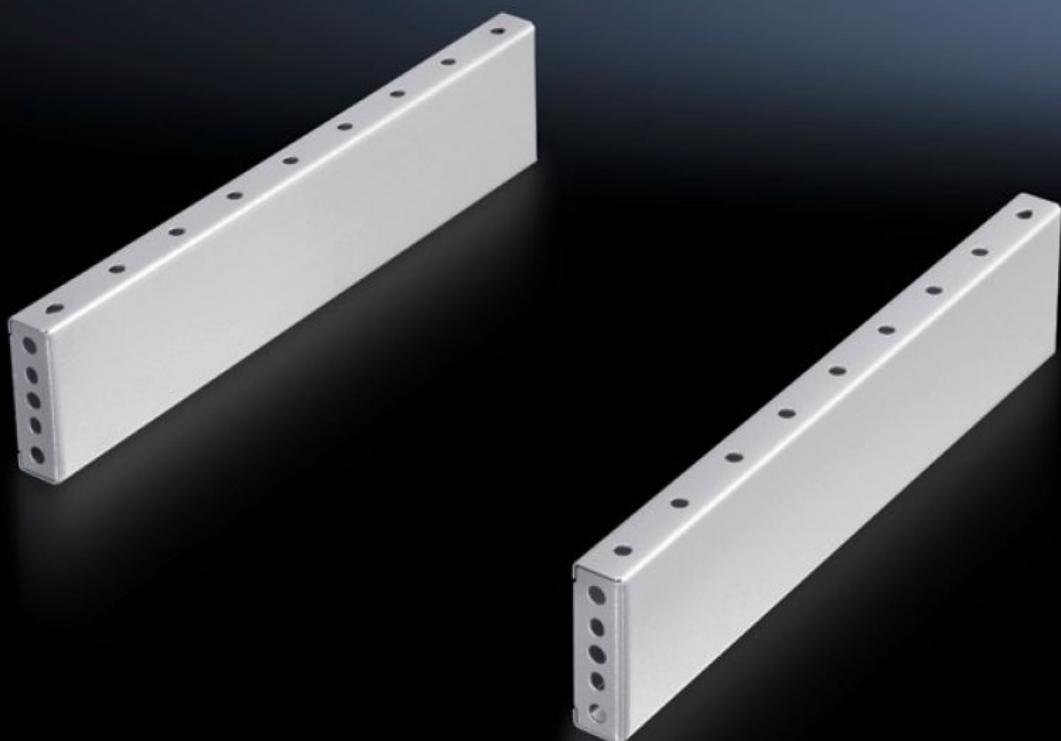

## TS 8601.085

Base/plinth trim panels, side, 100 mm

State: 2026-02-02 (Source: [rittal.com/ca-en](https://rittal.com/ca-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# TS 8601.085 - Base/plinth trim panels, side, 100 mm for base/plinth components, front and rear

To mount between the base/plinth components. For height 200 mm two 100 mm base/plinth trim panels can be used. Base/Plinth panels can be installed turned at 90° to provide stabilization for bayed base/plinth components.

## Features

|                       |   |
|-----------------------|---|
| Model No.             | TS 8601.085   |
| Product description   | To mount between the base/plinth components. For height 200 mm, two 100 mm base/plinth trim panels can be used.   |
| Material              | Carbon steel  |
| Surface finish        | Spray-finished  |
| Color                 | RAL 7035  |
| Supply includes       | 2 plinth/base trim panels<br>Assembly components  |
| Mounting tip          | 100 mm side trim panels can be installed rotated through 90° to provide stabilization for bayed base/plinth components. Base/plinth baying brackets are required here |
| Dimensions            | Height: 100 mm  |
| Suitable for          | Enclosure type: TS: = 800 mm<br>Enclosure type: SE<br>Enclosure type: CM<br>Enclosure type: TP<br>Enclosure type: PC<br>Enclosure type: IW<br>Enclosure type: TS IT   |
| Packaging unit        | 2 pc(s).  |
| Net weight            | 2.8   |
| Gross weight          | 3.46  |
| Customs tariff number | 94039910  |

# Features

---

EAN 4028177232686

---

E-Number Sweden E7239657

---

ECLASS 8.0 27182003