


Rittal – The System.

Faster – better – everywhere.

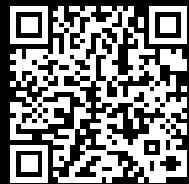

TS 8800.540


Cable duct

State: 2026-01-24 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



TS 8800.540 - Cable duct for vertical TS section

For mounting on a vertical enclosure profile or on two bayed enclosure profiles in the baying area.

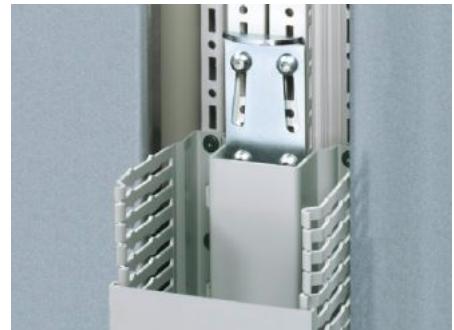

Features

| | |
|-----------------|---|
| Model No. | TS 8800.540 |
| Version | Width 100 mm, for assembly on two bayed enclosure sections in the baying area. |
| Benefits | <p>The cable duct fastening points are co-ordinated with the TS system hole pattern. This eliminates time-consuming drilling work that would be necessary with DIN ducts.</p> <p>The nominal break points of the bars are also designed in combination with the cable ducts for mounting plates.</p> <p>A further nominal break at the mounting plate height allows direct entry to the cable duct.</p> |
| Material | Hard PVC Flame-resistant, self-extinguishing |
| Color | Similar to RAL 7030 |
| Supply includes | Cable duct with cover |
| Bar width | 5.5 mm |
| Slot width | 4.5 mm |
| Note | Can be shortened for other enclosure sizes. |

Features

| | |
|-----------------------------|---|
| Dimensions | Width: 100 mm Height: 1,600 mm Depth: 80 mm |
| Suitable for | Enclosure type: TS VX SE PC IW Height: ≤ 1,800 mm |
| Operating temperature range | 60 °C |
| Packaging unit | 4 pc(s). |
| Net weight | 8.192 |
| Gross weight | 8.623 |
| Customs tariff number | 73269098 |
| EAN | 4028177238008 |
| ECLASS 8.0 | 27400703 |

Approvals

| | |
|--------------|---|
| Explanations | Declaration of conformity Declaration of conformity UK |
|--------------|---|
