


Rittal – The System.

Faster – better – everywhere.

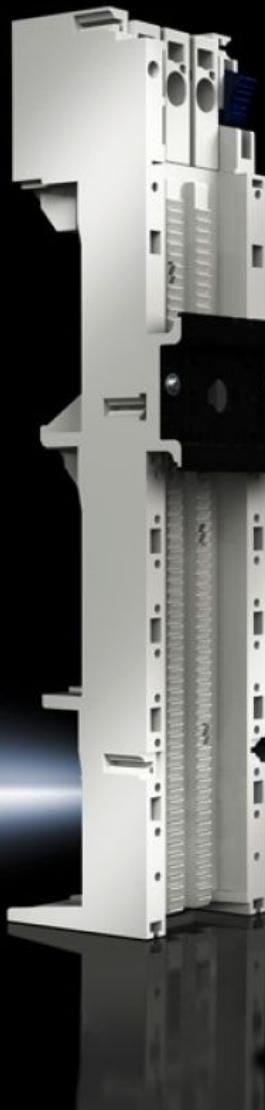

SV 9340.510

OM adapter

State: 2026-01-15 (Source: rittal.com/ca-en)



SV 9340.510 - OM adapter with tension spring clamp



Features

Model No.	SV 9340.510
Material	Polyamide Fire protection corresponding to UL 94-V0
Color	Chassis: RAL 7035
Rated current max.	32 A
Rated operating voltage	690 V, 3~
For bar systems with center-to-center spacing	60 mm
Support rail type	Without support frame, 1 x TS 45C
Number of poles	3-pole
Dimensions	Width: 45 mm Height: 208 mm
Connection of round conductors	1.5 - 6 mm ²
Support rails Qty/height	1 / 10 mm
Suitable for busbars	Height: 5, 10 mm
Packaging unit	1 pc(s).
Net weight	0.231
Gross weight	0.24
Copper weight (kg per piece)	0.027

Features

Customs tariff number 85369095

EAN 4028177502611

ETIM 9 EC001531

ECLASS 8.0 27370304

Approvals

Approvals ABS
DNV-GL
Lloyds Register of Shipping

Explanations Declaration of conformity
Declaration of conformity UK