


# Rittal – The System.

Faster – better – everywhere.

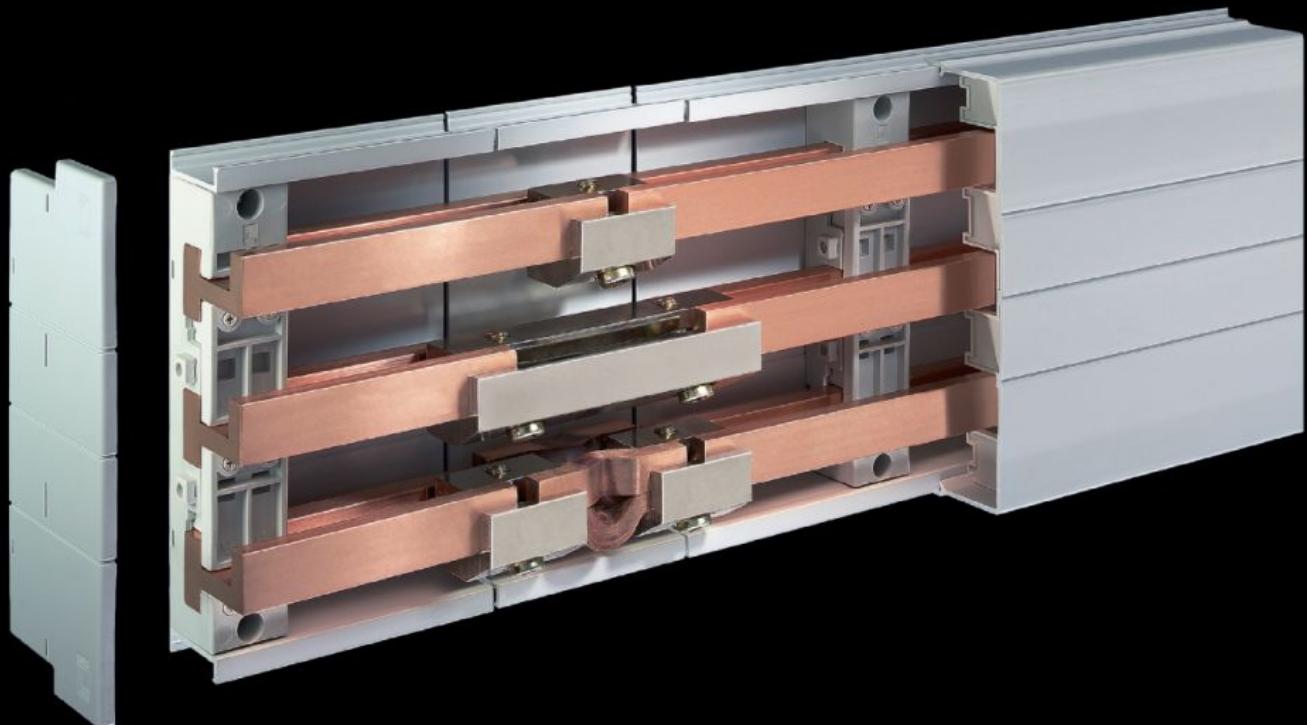

## SV 9342.004

## PLS Busbar Supports


State: 2026-02-03 (Source: [rittal.com/ca-en](https://rittal.com/ca-en))



FRIEDHELM LOH GROUP

# SV 9342.004 - PLS Busbar Supports

For PLS special busbars 800 A/1600 A, 3-pole and 4-pole.

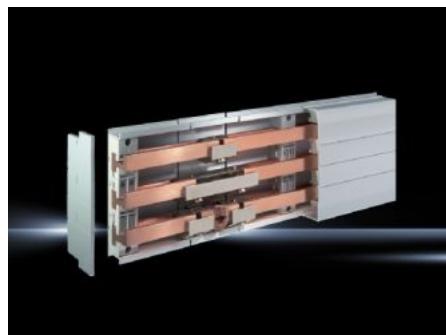

## Features

Model No.	SV 9342.004
Material	Polyamide Fire protection corresponding to UL 94-V0
Color	RAL 7035
Rated operating voltage	1000 V, 3~
Electrical UL ratings (SCCR)	65 kA - 480 V, support spacing 250 mm, busbars PLS 1600, circuit breaker max. 1200A, DIVQ/7
Note on Model No.:	The use of a base tray is required for UL applications. UL approval only applies in conjunction with AC application
Busbar support design	PLS 1600 PLUS
Number of poles	4-pole
Suitable for busbars	PLS 1600
Suitable for Model No.	3516.000 3527.000 3528.010 3529.000
With internal attachment	Yes
Center-to-center spacing of busbars	60 mm
Approvals	UL

## Features

---

Packaging unit 4 pc(s).

Net weight 2.2

Gross weight 2.321

Customs tariff number 85469010

EAN 4028177536760

ETIM 9 EC001166

ECLASS 8.0 27400607

## Approvals

---

Approvals ABS  
Lloyds Register of Shipping  
UL + C-UL (listed)

Explanations Declaration of conformity  
Declaration of conformity UK