

**Rittal – The System.**

Faster – better – everywhere.



**PK 9516.000**

**PK Polycarbonate Housings**

State: 2026-01-28 (Source: [rittal.com/ca-en](https://rittal.com/ca-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL


IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# PK 9516.000 - PK Polycarbonate Housings without knockouts

Wall-mounted enclosure of fiberglass-reinforced polycarbonate. Protection category IP 66. Covers feature quick-release fasteners for speedy maintenance. Self-extinguishing material for safety.

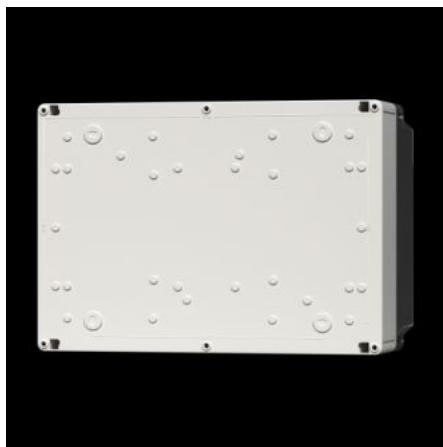

## Features

Model No.	PK 9516.000
Version	PK housing with closed cover
Product description	Use in ambient temperature range: -35°C...+80°C. The specified temperatures can be limited by the installed equipment.
Material	Housing: Fiber-glass reinforced polycarbonate Cover gray: Fiberglass-reinforced polycarbonate, all-round foamed PU seal Cover screws: Polyamide Insulating bungs: Polythene
Color	RAL 7035
Supply includes	Housing with cover Cover screws Insulating bungs for wall mounting screws
Protection category NEMA	NEMA 4X
Protection category IP to EN 60 529	IP 66

## Features

IK code	IK08
Dimensions	Width: 180 mm Height: 110 mm Depth: 165 mm
Operating temperature range	-35 °C...80 °C
Base material	Polycarbonate
Packaging unit	2 pc(s).
Net weight	1.174
Gross weight	1.373
Customs tariff number	94037000
EAN	4028177139572
ETIM 9	EC000261
ECLASS 8.0	27180101

## Approvals

Approvals	C-UL DNV-GL UL
Explanations	Declaration of conformity