


Rittal – The System.

Faster – better – everywhere.

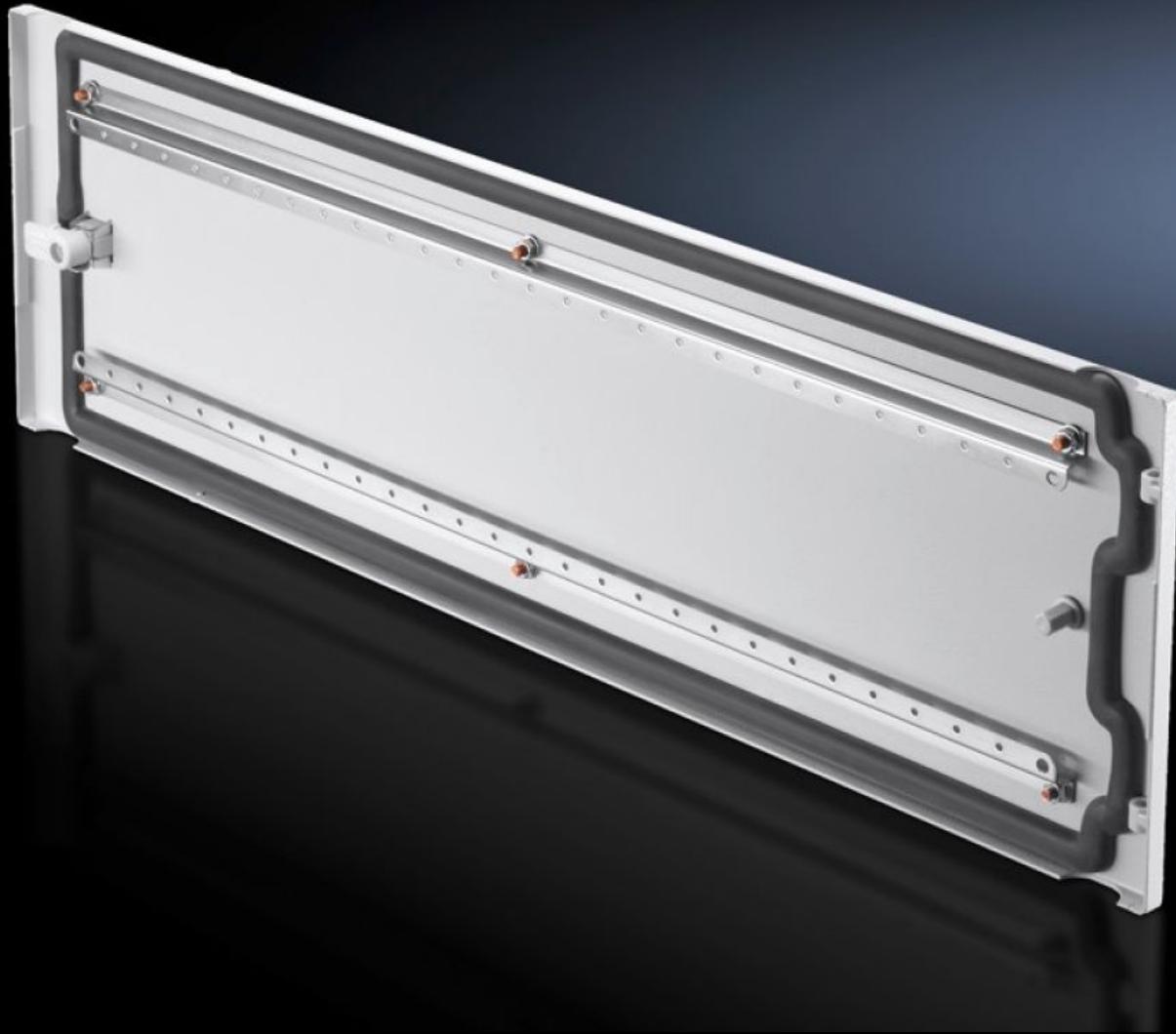

SV 9681.208

Perforated mounting strip

State: 2026-01-20 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL


IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

SV 9681.208 - Perforated mounting strip for partial door

For retro-fitting to partial doors, with 25 mm hole pattern for individual mountings on the rear of the door, e.g. cable ducts, conduit holders etc.

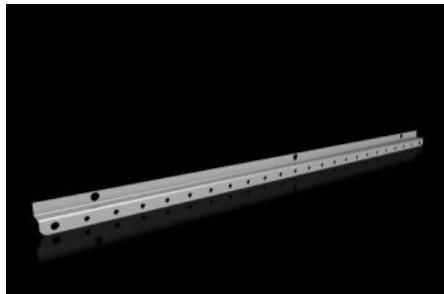

Features

Model No.	SV 9681.208
Product description	For retrofitting to partial doors. The perforated mounting strips have a 25 mm hole pattern and can be used for individual attachments such as cable ducts, hose holders, etc., and are used on the back of the doors. Hole diameter of the perforated mounting strip: 4.5 mm.
Material	Carbon steel, 1 mm
Surface finish	Zinc-plated
Supply includes	Assembly components
Length	598 mm
Dimensions	Length: 598 mm
Suitable for	Width: 800 mm
OUT_SUITABLE_FOR_PARTIAL_DO OR_HEIGHTS	150 - 800 mm
Packaging unit	10 pc(s).
Net weight	1.9
Gross weight	1.914
PCF/VE (cradle-to-gate)	6.9 kg CO ₂ eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared

Features

Customs tariff number 39269097

EAN 4028177930032

ETIM 9 EC000386

ECLASS 8.0 27400501

Approvals

Explanations Declaration of conformity UK