


# Rittal – The System.

Faster – better – everywhere.

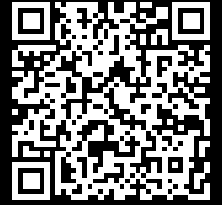

## KL 1529.010 Terminal boxes KL

State: 25/06/2026 (Source: [rittal.com/com-en](http://rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# KL 1529.010 - Terminal boxes KL Stainless steel

Terminal boxes, stainless steel 1.4301 (AISI 304), Protection category IP 66.

## Features

Model No.	KL 1529.010
Material	Enclosure: Stainless steel 1.4301 (AISI 304) Cover: Stainless steel 1.4301 (AISI 304), all-round foamed-in PU seal
Surface finish	Enclosure and cover: Brushed, grain 180
Supply includes	Enclosure with cover Quick-release fastener including plastic bushes
Protection category NEMA	NEMA 4X
Protection category to IEC 60 529	IP 66
IK Code	IK08
Dimensions	Width: 300 mm Height: 200 mm Depth: 120 mm
Material thickness - cover	1.25 mm
Material thickness - enclosure	1.25 mm
Lock	Number of locks: 4
Basic material	Stainless steel 1.4301 (AISI 304)
Packs of	1 pc(s).
Net weight	2.7 kg
Gross weight	2.975 kg
Customs tariff number	84879090
ETIM 9	EC000261
ETIM 8	EC000261
ECLASS 8.0	27180101

# Features

---

Product description	KL Terminal box, WHD: 300x200x120 mm, Stainless steel 1.4301, without mounting plate, with cover, without gland plate
---------------------	-----------------------------------------------------------------------------------------------------------------------

# Approvals

---

Approvals	Bureau Veritas DNV UL + C-UL (listed)
-----------	---------------------------------------------

---

Explanations	Declaration of conformity Declaration of conformity UK
--------------	-----------------------------------------------------------