


Rittal – The System.

Faster – better – everywhere.

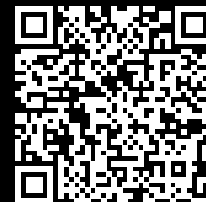

SG 2372.130

Signal pillar LED compact

State: 19/05/2024 (Source: [rittal.com/com-en](https://www.rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SG 2372.130 - Signal pillar LED compact

Extremely long service life of the LEDs, minimal assembly work and low warehousing costs.

Features

Model No.	SG 2372.130
Design	1-stage, red
Product description	Transmission angle: 3 x 120°, supplied state: Steady light. Flashing function controllable via PLC
Benefits	Complete, ready-to-connect solution Minimal build height Long LED service life Minimal assembly work and warehousing costs
Cable entry	Min. cable diameter: 3 mm Max. cable diameter: 6.5 mm
Diameter	72 mm
Type of electrical connection	Screw terminals
Light	LEDs
Rated insulation voltage	< 60 V DC
Dimensions	Height: 107 mm
Operating temperature range	-20 °C...70 °C
Protection category to IEC 60 529	IP 65
Rated operating voltage	24 V 24 V (DC)
Packs of	1 pc(s).
Weight/pack	0.22 kg
Customs tariff number	85311095
EAN	4028177490130
ETIM 7.0	EC001042

Features

ECLASS 8.0	27371230
------------	----------

Approvals

Approvals	C-UL UR
-----------	------------

Explanations	Declaration of conformity
--------------	---------------------------