


Rittal – The System.

Faster – better – everywhere.

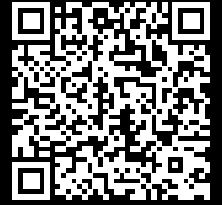

SZ 2565.300 Plastic gland plate

State: 26/06/2026 (Source: rittal.com/com-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2565.300 - Plastic gland plate with membranes, for AX

Simply pierce the plastic with a sharp object, and pull through the cable.

Features

| | |
|--|--|
| Model No. | SZ 2565.300 |
| Product description | Simply pierce the plastic with a sharp object, and pull through the cable. |
| Material | Plastic to UL 94-V0 |
| Colour | Similar to RAL 7035 |
| Note | The allocation of gland plate sizes is indicated on the relevant enclosures |
| Dimensions | Width: 301 mm Depth: 221 mm |
| To fit | Enclosure type: AX |
| Gland plate | Size: 5 |
| Protection category to IEC 60 529 | IP 66 if installed correctly |
| Type rating to UL 50E | Type 1 Type 12 |
| No. of cable entries and Ø (mm) min.-max. | 30 x 5-11 40 x 10-15 5 x 15-25 2 x 19-34 2 x 26-54 1 x 50-110 |
| Packs of | 1 pc(s). |
| Net weight | 0.585 kg |
| Gross weight | 0.59 kg |
| Customs tariff number | 39269097 |
| ETIM 9 | EC000211 |
| ETIM 8 | EC000211 |

Features

ECLASS 8.0

27142421

Product description

SZ Plastic gland plates, for AX, with membranes, WD: 301x221 mm,
for gland plates size 5

Approvals

Approvals

UL + C-UL - FTTA