


# Rittal – The System.

Faster – better – everywhere.

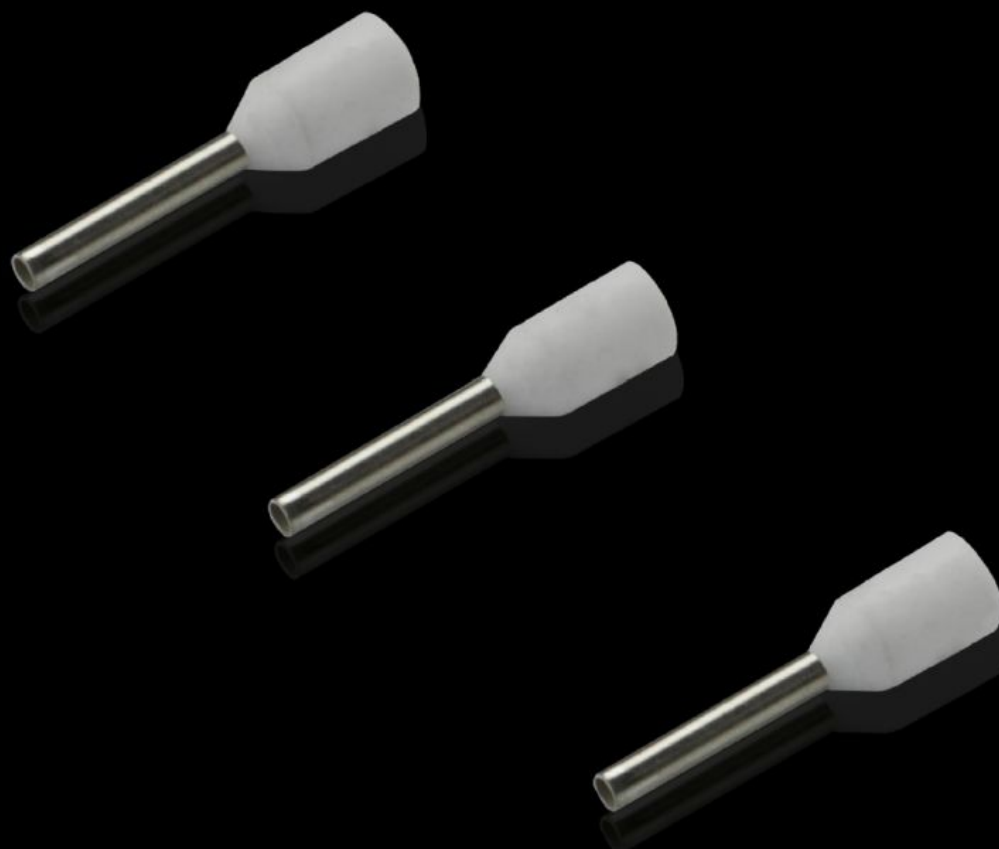

## AS 4050.742

## Wire end ferrules

State: 28/04/2024 (Source: [rittal.com/com-en](https://www.rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.742 - Wire end ferrules loose

With plastic collar.

## Features

Model No.	AS 4050.742
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	White
Length	8 mm
AWG	20
Internal diameter	2.9 mm
For cross-section	0.5 mm <sup>2</sup>
DIN colour code	Yes
Multinorm	Yes
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Delivery form	Loose
Packs of	500 pc(s).
Weight/pack	0.001 kg
Customs tariff number	85369010
EAN	4028177805101
ETIM 7.0	EC000005
ECLASS 8.0	36659290

# Approvals

---

Approvals

UL + C-UL (listed)

UR