


Rittal – The System.

Faster – better – everywhere.

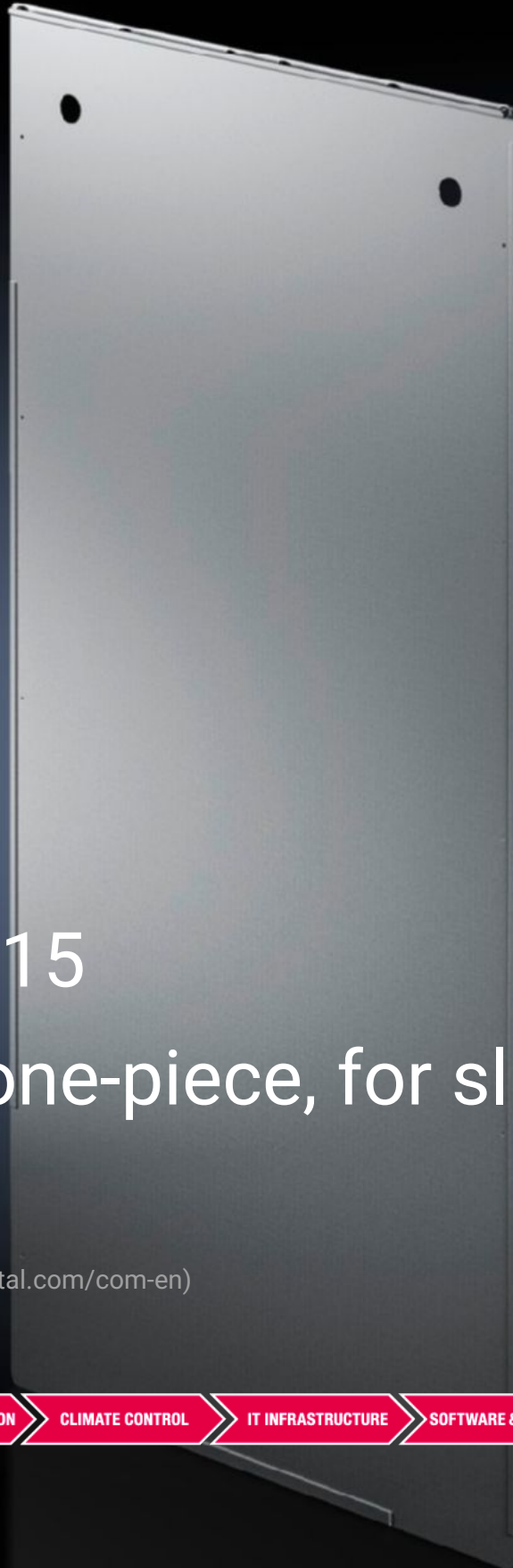

VX 5301.315

Partition, one-piece, for slide-in fixing

State: 08/07/2026 (Source: rittal.com/com-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 5301.315 - Partition, one-piece, for slide-in fixing for VX IT

Partition for VX IT. For rack mounting, suspended between two VX IT enclosures.



Features

| | |
|-------------------------------------|---|
| Model No. | VX 5301.315 |
| Product description | For rack mounting, suspended between two bayed enclosures. With one Ø 40 mm hole in the left-hand and right-hand corner areas for inserting cables, conduits etc. These drilled holes may be sealed with the enclosed cover caps. |
| Benefits | Simply slides into position |
| Material | Sheet steel, zinc-plated |
| Supply includes | Partition 2 cover caps |
| To fit | Enclosure type: VX IT Height: = 2,450 mm Depth: = 1,000 mm |
| Assembly instruction | A baying gap of 3 mm is required to insert the partition |
| Note | Use baying connector, external, 3 mm Not suitable for use in conjunction with a baying seal Any seals that may be present must be removed prior to installation |
| IP protection category to IEC 60529 | IP 20 (with fitted cover caps) |
| Packs of | 1 pc(s). |

Features

| | |
|-----------------------|---|
| Customs tariff number | 94039910 |
| ETIM 9 | EC002525 |
| ECLASS 8.0 | 27189234 |
| Product description | Partition, one-piece, insertable for VX IT, suspended between two bayed enclosures. For enclosure height 2,450 mm, for enclosure depth 1,000 mm, sheet steel, zinc-plated |