


# Rittal – The System.

Faster – better – everywhere.

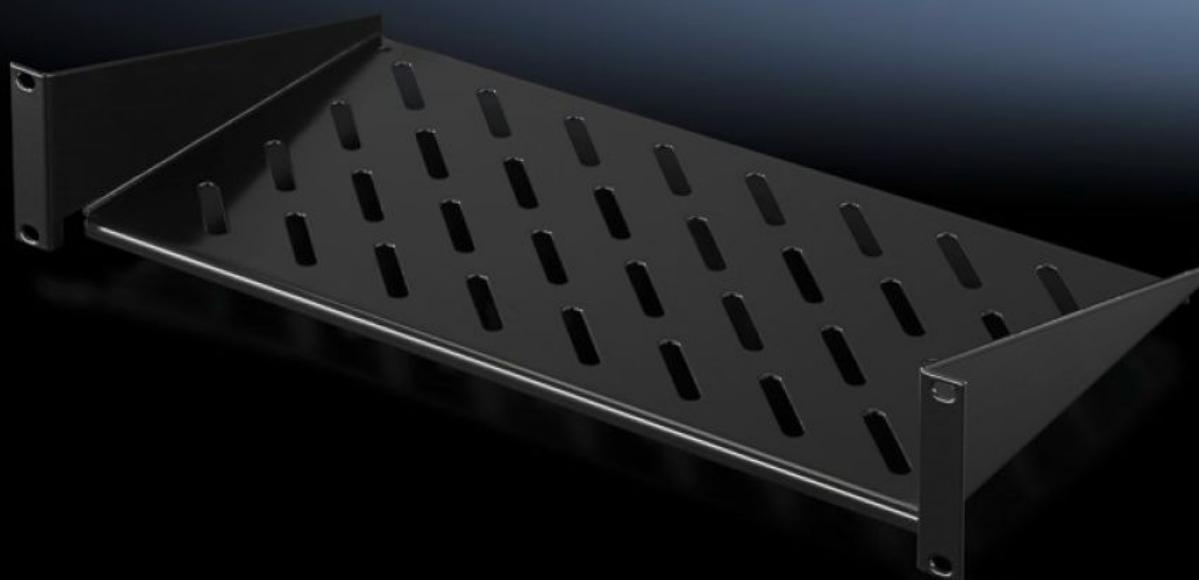

## DK 5501.625

### Component shelf 2 U, static installation

State: 01/02/2026 (Source: [ittal.com/com-en](https://www.ittal.com/com-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL



IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# DK 5501.625 - Component shelf 2 U, static installation

Component shelf 2 U, static installation for attachment to the 482.6 mm (19") system punchings.  
Load capacity: 25 kg.

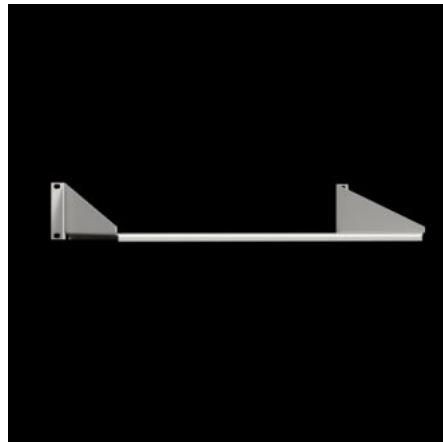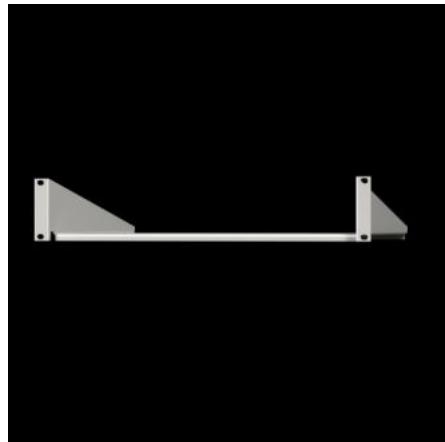

## Features

Model No.	DK 5501.625
Design	482.6 mm (19")
Product description	For mounting between 482.6 mm (19") mounting angles.
Material	Sheet steel
Surface finish	Spray-finished
Colour	RAL 9005
Load capacity	25 kg surface load, static
Note	Not suitable for combination with telescopic slides.
Dimensions	Width: 482.6 mm Depth: 400 mm
Packs of	1 pc(s).
Net weight	3.297
Gross weight	3.52
PCF per pack (cradle-to-gate)	11.4 kg CO <sub>2</sub> eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared

# Features

---

Customs tariff number 73269098

---

EAN 4028177679061

---

E-Number Sweden E7239586

---

ETIM 9 EC002620

---

ECLASS 8.0 27189261