


Rittal – The System.

Faster – better – everywhere.

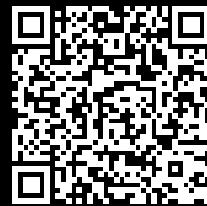

CP 7495.000

Twin castors

State: 15/01/2026 (Source: rittal.com/com-en)



FRIEDHELM LOH GROUP

CP 7495.000 - Twin castors

For mobile use, for mounting directly on the enclosure.

Features

| | |
|---|--|
| Model No. | CP 7495.000 |
| Product description | For mobile use, for mounting directly on the enclosure. |
| Colour | Black |
| Supply includes | 4 twin castors, 2 x with, 2 x without locks Assembly parts |
| Note on Model No. | A base/plinth adaptor is required for mounting on the VX base/ plinth A base/plinth adaptor is required for mounting on the TS base/ plinth. |
| To fit | Enclosure type: VX Enclosure type: VX IT Enclosure type: VX SE Enclosure type: PC Enclosure type: TP pedestals Enclosure type: IW Enclosure type: Data Rack Enclosure type: Chiller |
| Clearance floor | 125 mm |
| Max. load capacity (static) per component | 1,200 N |
| Dimensions | Thread: M12 x 20 |
| Packs of | 4 pc(s). |
| Net weight | 1.76 |
| Gross weight | 1.98 |
| Customs tariff number | 83024900 |
| EAN | 4028177131200 |
| E-Number Sweden | E7239729 |

Features

ETIM 9 EC002621

ECLASS 8.0 27189262

Tender text

Twin castors

Mounting on the frame

Suitable for:

VX, VX IT, VX SE, PC cabinet system, top console lower parts, Industrial workstation (IW), Data rack, Chiller

For mounting on the VX base, a base adapter for double twin castors is required (8100.770 or 8100.771)

Fitted to VX, AX, KX, TS, PS, ES & AP frames, PC enclosures,

Material: RAL 9005 (black)

Dimensions (W x H x D): 0 mm x 125 mm x 0 mm