


**Rittal – The System.**

Faster – better – everywhere.

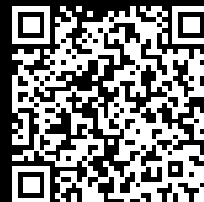

**TS 8612.780**

**TS punched rail 25 x 38 mm**

State: 15/05/2025 (Source: [rittal.com/com-en](http://rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 8612.780 - TS punched rail 25 x 38 mm

For heavy installations, with attachment holes. Installation options on the vertical TS enclosure section.



## Features

Model No.	TS 8612.780
Product description	For heavy installations, with attachment holes.
Material	Sheet steel, 3.0 mm
Surface finish	Zinc-plated
Supply includes	Assembly screws
Installation options	On the vertical TS, VX SE enclosure section With 9 mm round holes all round on a 25 mm pitch pattern For the external mounting angle of support rails, system support rails, C rails 30/15, cable clamp rails (right angle section), own assemblies
Note	In conjunction with the snap-on nut, particularly well-suited for dynamic connections
To fit	To fit width/depth: 800 mm
Packs of	2 pc(s).
Net weight	2.488
Gross weight	2.687
Customs tariff number	73269098
EAN	4028177429154

# Features

ETIM 9	EC002620
ECLASS 8.0	27189261