


Rittal – The System.

Faster – better – everywhere.

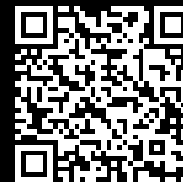

AS 4051.728 Ledningstyler

Stat: 23-11-2025 (Kilde: rittal.com/dk-da)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4051.728 - Ledningstykker løse

Med plastkrave.

Funktioner

Best.nr.	AS 4051.728
Produktbeskrivelse	Med plastkrave.
Tekniske data	Varmebestandig op til 105 °C
Materiale	E-Cu, galvanisk forsinket Plastkrave: Polypropylen
Farve	orange
Længde	10 mm
AWG	12
Indvendig diameter	4,8 mm
DIN-farvekode	Ja
Bemærk	UL-certificeret i forbindelse med de tilhørende værktøjer, som f.eks. crimpautomater Kontakt din Rittal forhandler for at få individuel rådgivning.
Normer	AEH DIN 46228
Leveringsform	løse
Pakkestørrelse	500 stk.
Nettovægt	0.5
Toldtarifnummer	85369010
EAN	4028177999985
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290

Godkendelser.

Godkendelser.

UL + C-UL (listed)

UR