
 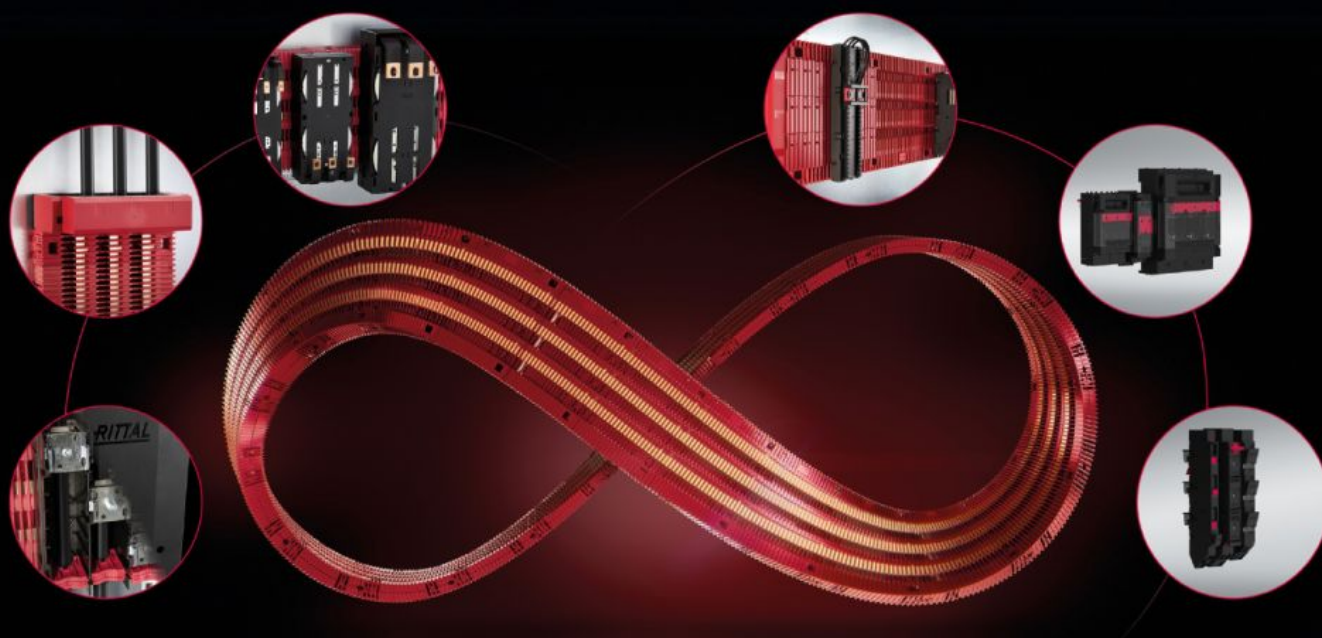


# Rittal – The System.

Faster – better – everywhere.



## RX 9360.503

# RiLineX Circuit-breaker component adaptor

Stat: 01-08-2025 (Kilde: [rittal.com/dk-da](http://rittal.com/dk-da))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# RX 9360.503 - RiLineX Circuit-breaker component adaptor

CB component adaptors for the RiLineX busbar platform in widths 81 to 140 mm. For mounting moulded-case circuit-breakers (MCCBs). Products are available in two variants: An "Easy-Fix" variant for user-friendly external mounting of switches from all standard manufacturers, and a "Universal" variant with U nuts for maximum flexibility.

## Funktioner

|                                    |                                                                                                                                                                                                                                               |
|------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Best.nr.                           | RX 9360.503                                                                                                                                                                                                                                   |
| Udgave                             | Easy Fix                                                                                                                                                                                                                                      |
| Fordele                            | Direct mounting of moulded-case circuit-breakers (MCCBs) on the board<br>Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm<br>Fast, simple pre-assembly of standard market switch types outside of the enclosure |
| Materiale                          | Polyamid (PA 6)<br>Brandegenskaber iht. UL 94                                                                                                                                                                                                 |
| Farve                              | RAL 9005<br>RAL 35745                                                                                                                                                                                                                         |
| Kapslingsklasse IP iht. IEC 60 529 | IP 2XB                                                                                                                                                                                                                                        |
| Mærkestrøm maks.                   | 160 A                                                                                                                                                                                                                                         |
| Mærkestrøm (UL)                    | 125 A                                                                                                                                                                                                                                         |
| Mærkestødspænding Uimp             | 12 kV                                                                                                                                                                                                                                         |
| Rated voltage                      | 690 V AC<br>690 V DC<br>600 V AC (UL)                                                                                                                                                                                                         |
| Rated insulation voltage           | 1.000 V                                                                                                                                                                                                                                       |
| Overspændingskategori              | 4                                                                                                                                                                                                                                             |
| Forureningsgrad                    | 3                                                                                                                                                                                                                                             |
| Antal poler                        | 3-polet                                                                                                                                                                                                                                       |

# Funktioner

|                                    |                                                |
|------------------------------------|------------------------------------------------|
| Ledningsafgang                     | foroven                                        |
| Tilslutningstype (elektrisk)       | Rammeklemme                                    |
| Passende til skinner               | RiLineX<br>RiLine60                            |
| Frekvens på grundsvingning         | 50...60 Hz                                     |
| Luftfugtighed (ikke kondenserende) | 10...90 %                                      |
| Passer til skinner                 | 15 x 5/10<br>20 x 5/10<br>30 x 5/10            |
| Driftstemperatur                   | -25 °C...55 °C                                 |
| Opbevaringstemperatur              | -25 °C...75 °C                                 |
| Dimensioner                        | Bredde: 81 mm<br>Højde: 252 mm<br>Dybde: 63 mm |
| Pakkestørrelse                     | 1 stk.                                         |

## Godkendelser.

|               |                    |
|---------------|--------------------|
| Godkendelser. | UL + C-UL (listed) |
|---------------|--------------------|