
 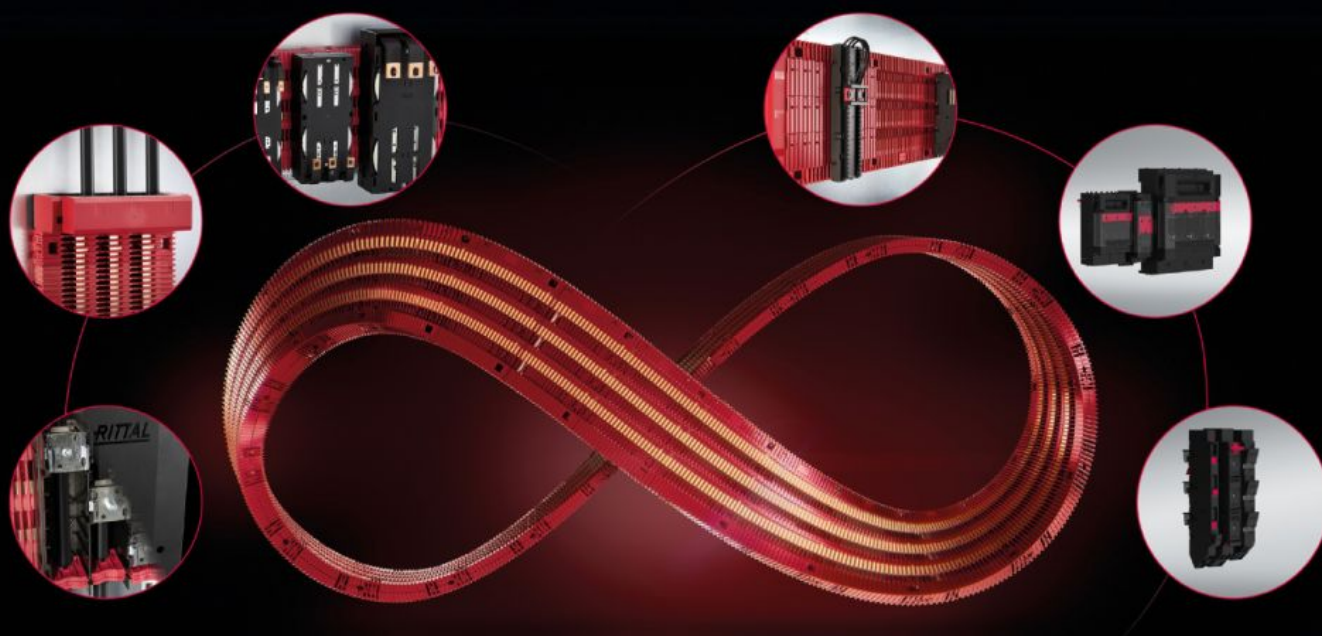


Rittal – The System.

Faster – better – everywhere.



RX 9360.513

RiLineX Circuit-breaker component adaptor

Stat: 31-07-2025 (Kilde: rittal.com/dk-da)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.513 - RiLineX Circuit-breaker component adaptor

CB component adaptors for the RiLineX busbar platform in widths 81 to 140 mm. For mounting moulded-case circuit-breakers (MCCBs). Products are available in two variants: An "Easy-Fix" variant for user-friendly external mounting of switches from all standard manufacturers, and a "Universal" variant with U nuts for maximum flexibility.

Funktioner

Best.nr.	RX 9360.513
Udgave	Easy Fix
Fordele	Direct mounting of moulded-case circuit-breakers (MCCBs) on the board Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
Materiale	Polyamid (PA 6) Brandegenskaber iht. UL 94
Farve	RAL 9005 RAL 35745
Kapslingsklasse IP iht. IEC 60 529	IP 2XB
Mærkestrøm maks.	250 A
Mærkestrøm (UL)	210 A
Mærkestødspænding Uimp	12 kV
Rated voltage	690 V AC 690 V DC 600 V AC (UL)
Rated insulation voltage	1.000 V
Overspændingskategori	4
Forureningsgrad	3
Antal poler	3-polet

Funktioner

Ledningsafgang	foroven
Tilslutningstype (elektrisk)	Skrue M8
Passende til skinner	RiLineX RiLine60
Frekvens på grundsvingning	50...60 Hz
Luftfugtighed (ikke kondenserende)	10...90 %
Passer til skinner	15 x 5/10 20 x 5/10 30 x 5/10
Driftstemperatur	-25 °C...55 °C
Opbevaringstemperatur	-25 °C...75 °C
Dimensioner	Bredde: 105 mm Højde: 252 mm Dybde: 63 mm
Pakkestørrelse	1 stk.

Godkendelser.

Godkendelser.	UL + C-UL (listed)
---------------	--------------------