

# Rittal – The System.

Faster – better – everywhere.



## SZ 2563.200

# Plastic gland plate, modular

State: 18/04/2026 (Source: [rittal.com/gr-en](http://rittal.com/gr-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2563.200 - Plastic gland plate, modular with metric knockouts, for AX

Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frame allow the cable gland to be installed directly (modular).

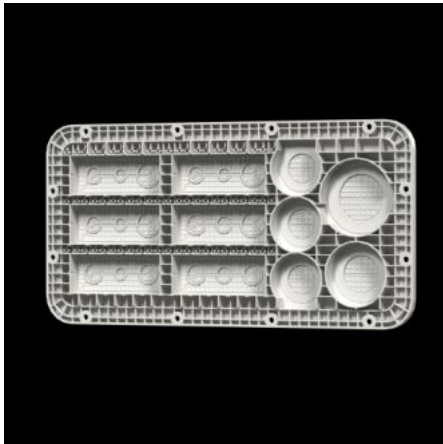

## Features

Model No.	SZ 2563.200
Product description	Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frame allow the cable gland to be installed directly (modular).
Material	Plastic to UL 94-V0
Colour	RAL 7035
Number of rectangular cutouts information	1 rectangular cut-out can hold 10 small seal inserts
Number of rectangular cutouts	4
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	4 x M12 3 x M16 5 x M20 3 x M25 1 x M32 1 x M40

# Features

Dimensions	Width: 447 mm Depth: 149 mm
To fit	Enclosure type: AX
Gland plate	Size: 3
Operating temperature range	-40 °C...80 °C
Protection category to IEC 60 529	IP 66 if installed correctly
Type rating to UL 50E	Type 1 Type 12
Packs of	1 pc(s).
Net weight	0.42 kg
Gross weight	0.48 kg
Customs tariff number	39269097
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ Plastic gland plates, for AX, for cable entry, modular, pre-punched, WD: 447x149 mm, for gland plates size 3

# Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------