


Rittal – The System.

Faster – better – everywhere.

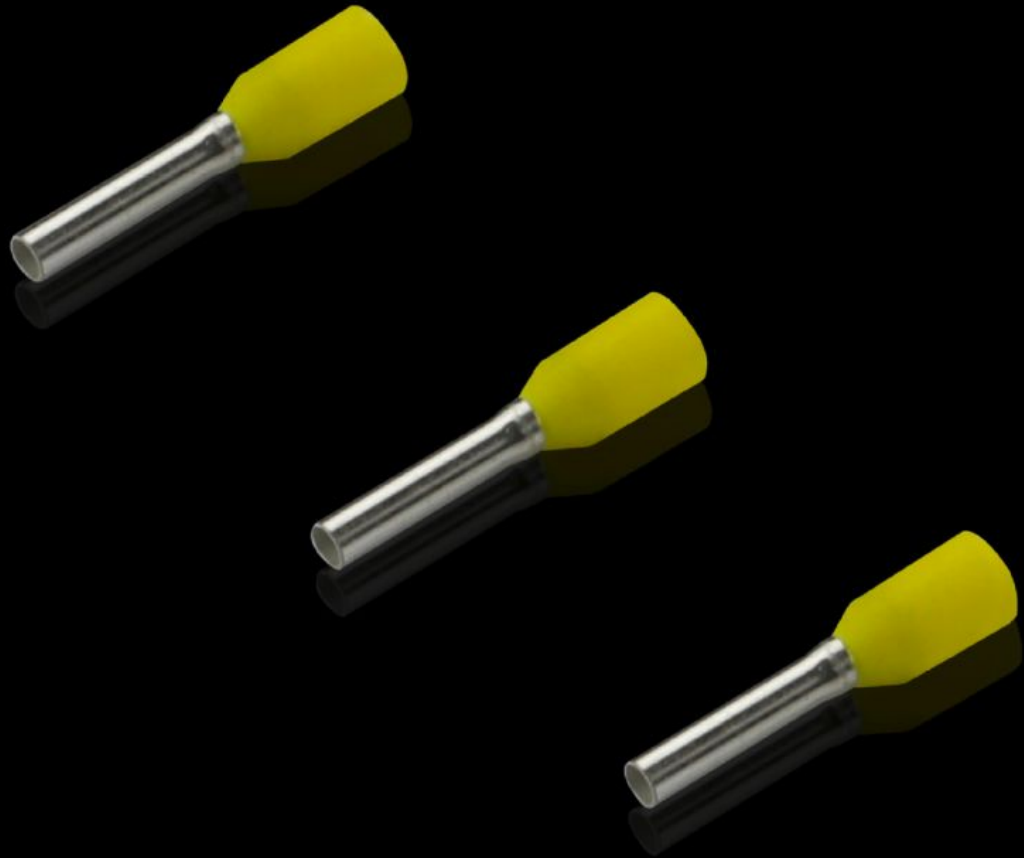

AS 4050.769 Wire end ferrules

State: 05/04/2026 (Source: rittal.com/gr-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.769 - Wire end ferrules loose

With plastic collar.

Features

| | |
|--------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------|
| Model No. | AS 4050.769 |
| Product description | With plastic collar. |
| Technical specifications | Heat-resistant to 105 °C |
| Material | E-Cu, galvanic tin-plated Plastic collar: Polypropylene |
| Colour | Yellow |
| Length | 8 mm |
| AWG | 18 |
| Internal diameter | 3 mm |
| Rittal colour code | Yes |
| For cross-section | 1 mm ² |
| Note | UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant. |
| Standards | AEH DIN 46228 |
| To fit Model No. | 4051.205 4051.210 4050.452 |
| Delivery form | Loose |
| Packs of | 500 pc(s). |
| Net weight | 0.5 kg |
| Gross weight | 0.049 kg |
| Customs tariff number | 85369010 |
| ETIM 9 | EC000005 |

Features

| | |
|---------------------|--------------------------------------------------------------------------------------------------|
| ETIM 8 | EC000005 |
| ECLASS 8.0 | 36659290 |
| Product description | Wire end ferrules for wire processing, 1 mm ² , AWG 18, 8 mm, yellow, loose, 500 pcs. |

Approvals

| | |
|-----------|--------------------------|
| Approvals | UL + C-UL (listed) UR |
|-----------|--------------------------|
