


Rittal – The System.

Faster – better – everywhere.

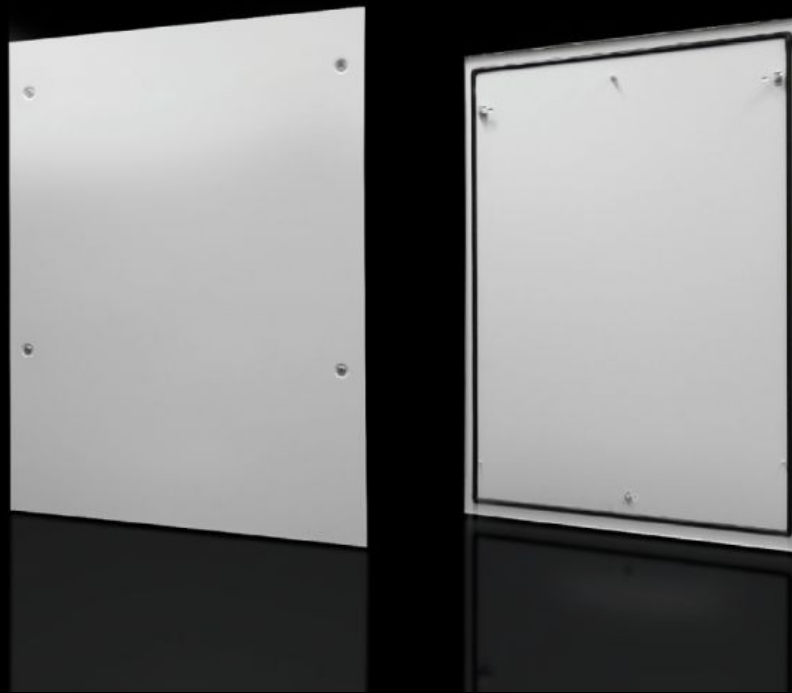

DK 7824.128 Side panel, lockable

State: 21/06/2026 (Source: rittal.com/gr-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7824.128 - Side panel, lockable for TS, TS IT

Side panel, lockable, sheet steel, for TS.



Features

| | |
|-----------------------|---|
| Model No. | DK 7824.128 |
| Product description | Simply locate from above. Lock with security lock no. 3524 E. Earthing bolt with contact track. |
| Material | Sheet steel |
| Surface finish | Spray-finished |
| Colour | RAL 7035 |
| Supply includes | 2 side panels each with 4 security locks no. 3524 E |
| To fit | Enclosure type: TS IT TX CableNet TS Height: 1,200 mm Depth: 800 mm |
| Basic material | Sheet steel |
| Packs of | 2 pc(s). |
| Net weight | 24 kg |
| Gross weight | 25.8 kg |
| Customs tariff number | 94039910 |
| ETIM 9 | EC002524 |
| ECLASS 8.0 | 27182101 |

Features

Product description

DK Side panel, For TS, TS IT, lockable, HxD: 1200x800 mm, RAL 7035

Tender text

Side panel, plug-type, for TS
H x D = 1200 x 800 mm, RAL 7035

Side panel fitted with a T-lock.
Material: Sheet steel, spray finished in RAL 7035
For 1200 mm x 800 mm enclosures