


Rittal – The System.

Faster – better – everywhere.

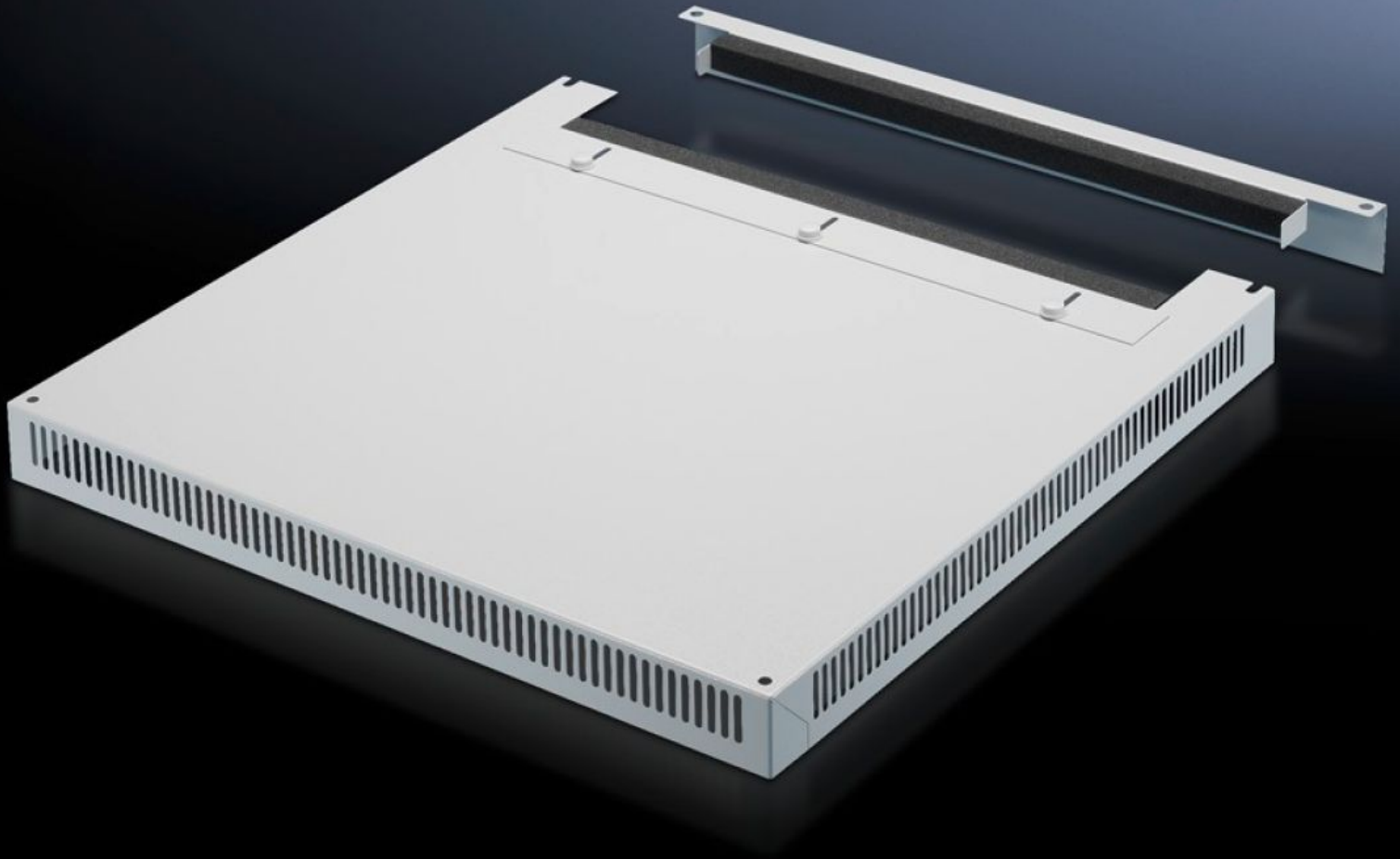

DK 7826.689

Roof plate, vented

State: 04/06/2026 (Source: rittal.com/gr-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7826.689 - Roof plate, vented for TS, TS IT

In exchange for the standard roof, with and without cable entry.

Features

| | |
|-----------------------|--|
| Model No. | DK 7826.689 |
| Design | Two-part with cable entry |
| Product description | In exchange for the standard roof. 72 mm high roof plate, all-round vent slots, clamp strip for cable entry. The two-piece design with cable entry allows convenient retrofitting. |
| Material | Sheet steel |
| Colour | RAL 7035 |
| To fit | Enclosure type: TS TS IT Width: 600 mm Depth: 800 mm |
| Packs of | 1 pc(s). |
| Net weight | 8.737 kg |
| Gross weight | 9.197 kg |
| Customs tariff number | 94039910 |
| ETIM 9 | EC000744 |
| ECLASS 8.0 | 27182405 |
| Product description | DK-TS8 Roof plate, WxD: 600x800 mm, 2-part, For cable entry |

Tender text

Vented roof plate, for TS, TS IT

W x D = 600 x 800 mm, two-piece

Material: Sheet steel, spray finished in RAL 7035

Dimensions (W x H x D): 600 mm x 0 mm x 800 mm