


# Rittal – The System.

Faster – better – everywhere.

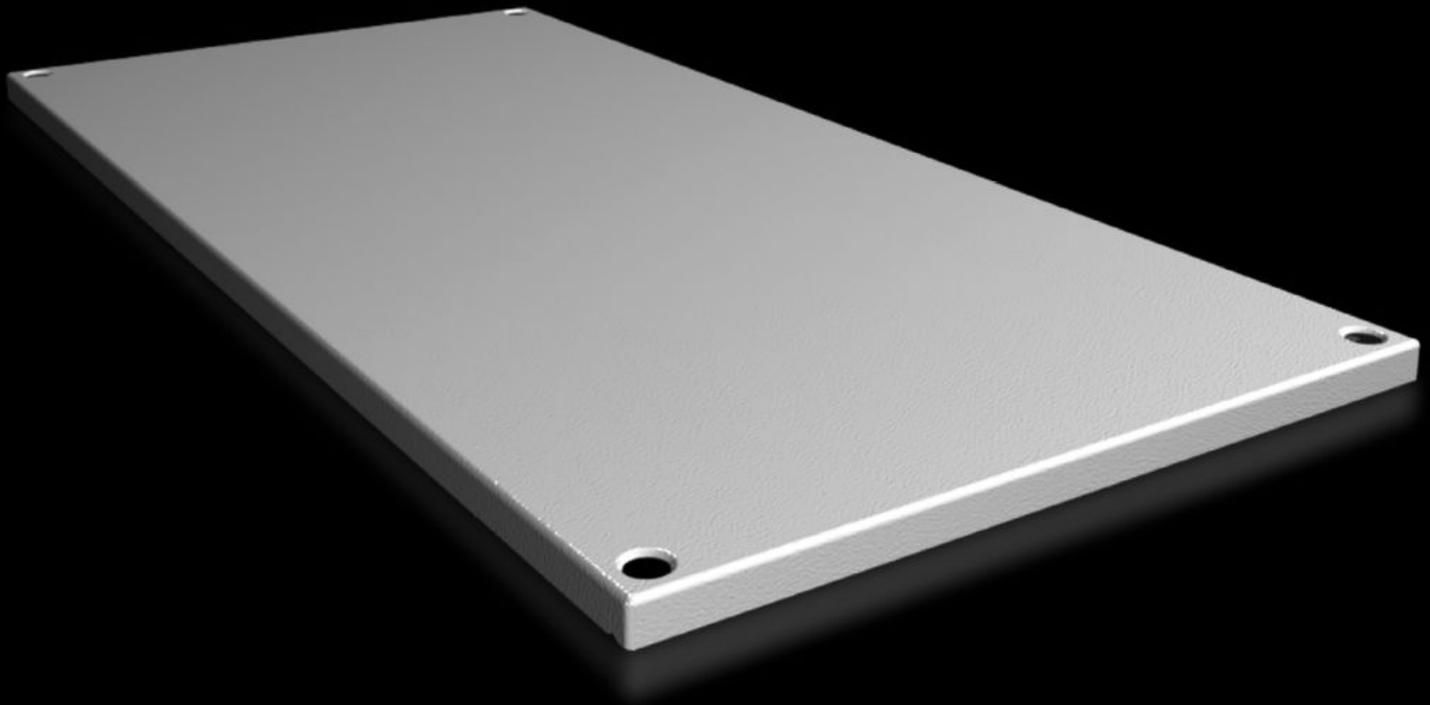

## SV 9681.648

## Roof plate IP 55, solid

State: 27/02/2026 (Source: [rittal.com/gr-en](http://rittal.com/gr-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 9681.648 - Roof plate IP 55, solid for VX, VX IT

For enclosures without roof plate and in exchange for the standard roof in other enclosures.

## Features

|                       |                                                                          |
|-----------------------|--------------------------------------------------------------------------|
| Model No.             | SV 9681.648                                                              |
| Product description   | For enclosures without roof plate and in exchange for the standard roof. |
| Material              | Sheet steel, 1.5 mm                                                      |
| Surface finish        | Textured paint                                                           |
| Colour                | RAL 7035                                                                 |
| Supply includes       | Assembly parts                                                           |
| To fit                | Width: = 400 mm<br>Depth: = 800 mm                                       |
| Packs of              | 1 pc(s).                                                                 |
| Net weight            | 3.6 kg                                                                   |
| Gross weight          | 4.9 kg                                                                   |
| Customs tariff number | 94039910                                                                 |
| ETIM 9                | EC000744                                                                 |
| ECLASS 8.0            | 27182405                                                                 |
| Product description   | SV Roof plate for VX, width x depth 400x800 mm, IP 55                    |

## Approvals

|              |                              |
|--------------|------------------------------|
| Explanations | Declaration of conformity UK |
|--------------|------------------------------|