


Rittal – The System.

Faster – better – everywhere.

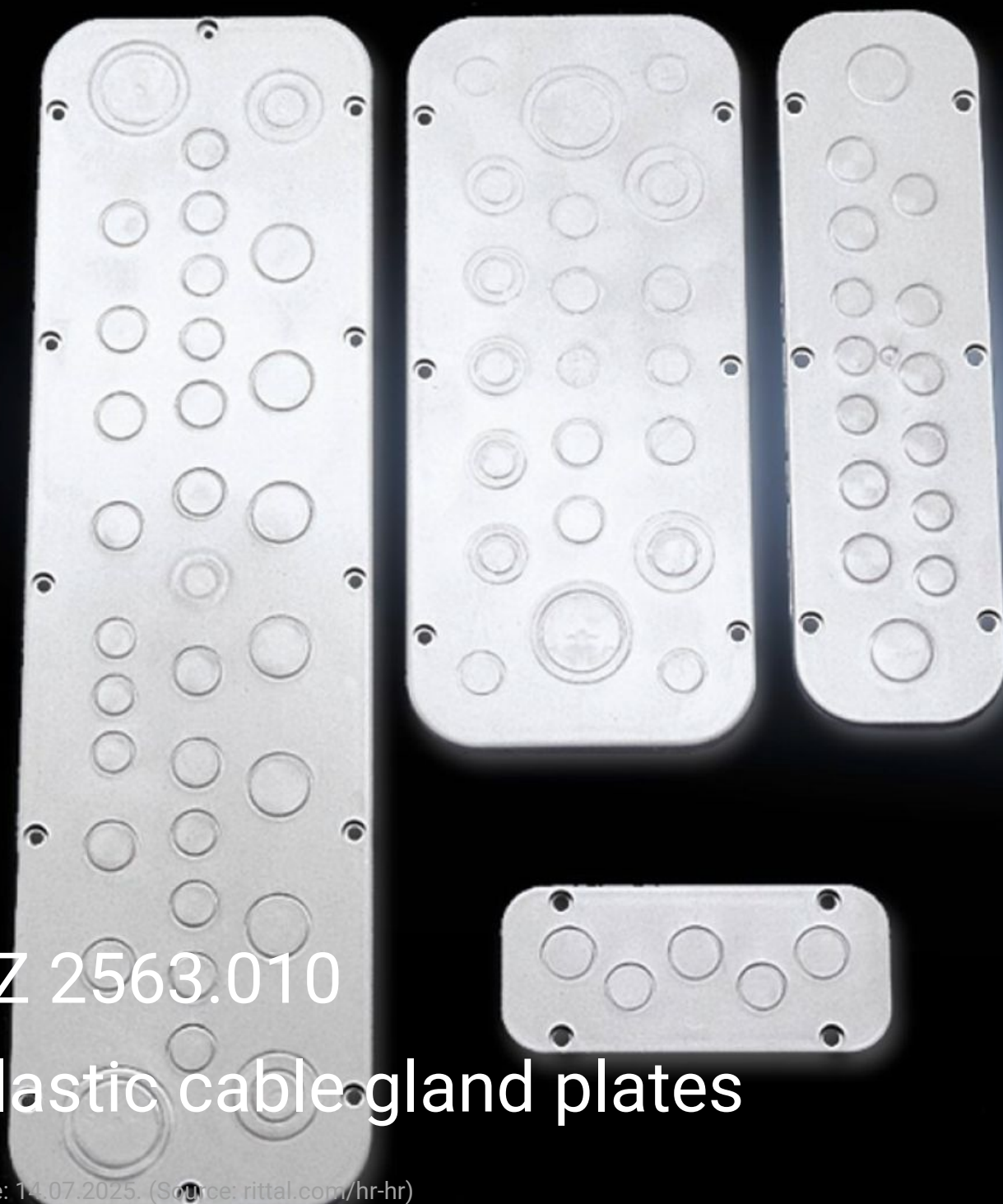

SZ 2563.010

Plastic cable gland plates

State: 14.07.2025. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2563.010 - Plastic cable gland plates with metric knockouts

With pre-punched holes for cable glands.

Features

Model No.	SZ 2563.010
Product description	With pre-punched holes for cable glands. Use seal for standard gland plates.
Colour	RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	2 x M12 4 x M16 8 x M20 13 x M25 6 x M32 4 x M40 2 x M50
Dimensions	Width: 530 mm Depth: 149 mm
To fit	Enclosure type: AE
Gland plate	Size: 5
Operating temperature range	-40 °C...70 °C
Protection category to IEC 60 529	IP 55 if installed correctly
Number knockouts	2 4 8 13 6 4 2

Features

Metric diameter	M12
	M16
	M20
	M25
	M32
	M40
	M50
Packs of	5 pc(s).
Net weight	1.75
Gross weight	1.949
Customs tariff number	39269097
EAN	4028177550285
E-Number Sweden	E3404764
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421